



YSH3429 Compression H-Tap Connector

By Burndy
Catalog # [YSH3429](#)

Copper Compression Double H - Tap Connector, 1/0 AWG - 250 kcmil (Tap 1), 1-6 AWG (Tap 2), 8-14 AWG (Tap 3), 4/0 AWG - 500 kcmil (Run)

Features

- Accommodates a wide range of Run/Tap Copper cable combinations including both flexible and code combinations allowing maximum flexibility
- Tap grooves function independently from each other, use of one tap is required, balance may be used or left empty

Application


For High Voltage (15 KV) Power Cables With Copper Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Flex G Run Range	4/0 AWG-500 kcmil
Conductor - Copper Flex G Run	• 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil
Conductor - Copper Flex H Run Range	4/0 AWG-500 kcmil
Conductor - Copper Flex H Run	• 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil
Conductor - Copper Str Run Range	4/0 AWG-500 kcmil
Conductor - Copper Flex G Tap Range	1/0 AWG-250 kcmil
Conductor - Copper Str Run	• 4/0 AWG • 250 kcmil

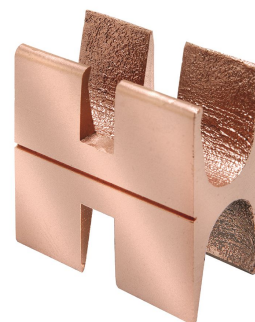

Conductor - Copper Flex G Tap	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Flex H Tap Range	1/0 AWG-250 kcmil
Conductor - Copper Flex H Tap	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Str Tap Range	1/0 -250 kcmil
Conductor - Copper Str Tap	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil

Configuration

Connector Type	H-Tap
----------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	56.6 mm
Dimension - Height inch	2.23 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Strip Length inch	1 1/2
Dimension - Width mm	33 mm
Dimension - Width inch	1.31 in
Dimension - Length Overall inch	3.00 in

General

Trade Name	CRIMPIT™
Die Index	1104
Plated	Yes
Color Code	Brown
Sub Brand	CRIMPIT
Product Type	Compression

UPC	781810038406
Type	Taps
Material	Copper
Plating Type	Tin
UPC 12 Digit	781810038406
UPC 14 Digit GTIN	00781810038406

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1920
Carton Quantity	20

Product Assets

[Catalog \[English\]](#)



A Hubbell brand