

YSH3931 Compression H-Tap Connector

By Burndy
Catalog # [YSH3931](#)

Copper Splice, 750 - 350 Kcm (Run), 4/0 - 1/0 AWG (350-1/0)
(Tap 1), #1-#6 AWG (1-8) (Tap 2), #2-#14 AWG (2-14) (Tap 3), KR
Index

Features


- Accommodates a wide range of Run/Tap Copper cable combinations including both flexible and code combinations allowing maximum flexibility
- Tap grooves function independently from each other, use of one tap is required, balance may be used or left empty

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Flex G Run Range	350 kcmil-700 kcmil
Conductor - Copper Flex G Run	• 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex H Run Range	350 kcmil-700 kcmil
Conductor - Copper Flex H Run	• 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Str Run Range	350 kcmil-750 kcmil
Conductor - Copper Flex G Tap Range	1/0 AWG-350 kcmil
Conductor - Copper Str Run	• 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil

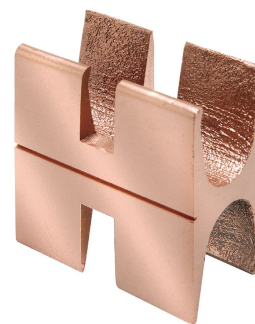

Conductor - Copper Flex G Tap	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
-------------------------------	---

Conductor - Copper Flex H Tap Range	1/0 AWG-350 kcmil
-------------------------------------	-------------------

Conductor - Copper Flex H Tap	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
-------------------------------	---

Conductor - Copper Str Tap Range	1/0 -350 kcmil
----------------------------------	----------------

Conductor - Copper Str Tap	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
----------------------------	---

Configuration

Connector Type	H-Tap
----------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height mm	75.4 mm
Dimension - Height inch	2.97 in
Package Weight	0.000 lb.
Dimension - Width mm	38 mm
Dimension - Width inch	1.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - Length Overall inch	3.00 in
Dimension - Strip Length inch	1 1/2

General

Plated	Y
Color Code	Yellow
Die Index	KR

UPC	781810038413
Type	Taps
Material	Copper
Plating Type	Tin
UPC 12 Digit	781810038413
UPC 14 Digit GTIN	00781810038413

Logistics

Minimum Pack Quantity	20
Pallet Quantity	960
Carton Quantity	20

Product Assets

[Catalog \[English\]](#)



A Hubbell brand