




YSM292, Uninsulated Parallel Splice For 275,000 - 211,500 cmils

By Burndy
Catalog # [YSM292](#)

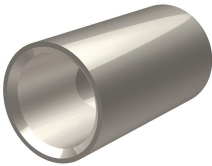

Uninsulated Parallel Splice For 275,000 - 211,500 cmils

Features

- Seamless tubing
- Beveled barrel for ease of wire entry
- Tin plated
- Parallel design results in only one crimp necessary
- Uninsulated barrel provides an economical termination solution when insulation is not specified

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	275,000 - 211,500 cmils
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Parallel Splice
----------------	-----------------

Dimensions

Dimension - Outside Diameter	0.75 in
inch	
Dimension - Strip Length	1-7/16
Dimension - Length Overall	1.38 in
inch	

General

Trade Name	HYLINK™
Plated	Y
Feature - Barrel Style	Chamfered
UPC 12 Digit	781810083680
UPC 14 Digit GTIN	00781810083680
Material	Copper
Plating Type	Tin
UPC	781810083680

Logistics

Minimum Pack Quantity	100
Carton Quantity	100
Pallet Quantity	23200

Product Assets

[Catalog \[English\]](#)