


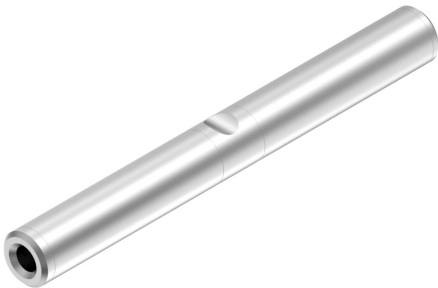

YTS39RT43RSHT, Full Tension ACSS EHV Splice Kit

By Burndy
Catalog # [YTS39RT43RSHT](#)

Full Tension ACSS EHV Splice Kits, YTS39RTHT Aluminium Sleeve (Qty. 1), YTS43RS Steel Sleeve (Qty. 1), PARAKEET 556.5 (24/7) kcmil; DOVE 556.5 (26/7) kcmil



Features

- Full Tension Compression ACSS EHV Splice Kit

Application

For ACSS Conductor, Corona free operation up to 550 KV

Specifications

Certification - CSA Approved No

Conductor

Conductor - Material	Aluminum
Conductor - ACSS Str Size Range	556.5 (24/7) kcmil-556.5 (26/7) kcmil
Conductor - ACSS Str Size	• PARAKEET 556.5 (24/7) kcmil • DOVE 556.5 (26/7) kcmil

Configuration

Connector Type Splice

Current

Voltage - Maximum 550 kV

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	2.47 in
Dimension - Outside Diameter inch	1.50 in
Dimension - Length Overall inch	28.74 in

General

Trade Name	HYSPLICE™
Die Index	• 722 • 723
Die Type	L722 for Aluminium Sleeve, L723 Steel Sleeve
UPC	621945461611
Material	Aluminum
UPC 12 Digit	781810515549
UPC 14 Digit GTIN	00781810515549

Logistics

Minimum Pack Quantity 1

Product Assets

[Catalog \[English\]](#)