


YTU25R4W, Aluminum T-Tap Connector

By Burndy

Catalog # [YTU25R4W](#)

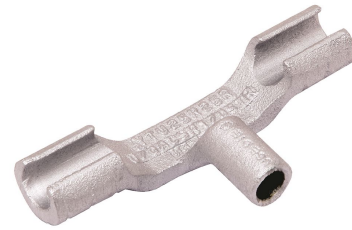

Al Compression T-Tap Connector, 1/0 AWG ACSR/Al/Cu(Run), #6 ACSR,6201,5005, #4 AWG, #4 Sol. Al/Cu(Tap)

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Cmpt Run Range	1/0 AWG
Conductor - ACSR Cmpt Run	1/0 AWG
Conductor - Copper Str Run Range	1/0
Conductor - Copper Str Run	1/0
Conductor - AAAC 5005 Tap Range	30.58 (7) kcmil
Conductor - AAAC 5005 Tap	30.58 (7) kcmil
Conductor - AAAC 6201 Run Range	123.3 (7) kcmil
Conductor - AAAC 6201 Run	123.3 (7) kcmil
Conductor - AAAC 6201 Tap Range	30.58 (7) kcmil
Conductor - AAAC 6201 Tap	30.58 (7) kcmil
Conductor - Copper Solid Tap Range	4 AWG
Conductor - Copper Solid Tap	4 AWG
Conductor - AL Str Run Range	1/0 AWG
Conductor - AL Str Run	1/0 AWG
Conductor - AAAC 5005 Run Range	123.3 (7) kcmil
Conductor - AAAC 5005 Run	123.3 (7) kcmil
Conductor - AL Str Tap Range	4 AWG
Conductor - AL Str Tap	4 AWG
Conductor - ACSR Cmpt Tap Range	6 AWG
Conductor - ACSR Cmpt Tap	6 AWG
Conductor - ACSR Str Run Range	80 (8/1) Grouse kcmil

Conductor - Copper Str Tap Range	4 AWG
Conductor - Copper Str Tap	4 AWG
Conductor - ACSR Str Run	80 (8/1) Grouse kcmil

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	60.3 mm
Dimension - Height inch	2.375 in
Dimension - Height fraction	2-3/8 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	124 mm
Dimension - Length Overall inch	4.875 in

General

Plated	Y
Die Index Run Side	C
UPC	781810155004
Die Index Tap Side	BG
Prefilled Oxide Inhibitor	Y
Material	Aluminum Alloy
Plating Type	Tin - Hot Dipped
UPC 12 Digit	781810155004
UPC 14 Digit GTIN	00781810155004

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)