




YTU30R30R, Aluminum T-Tap Connector

By Burndy
Catalog # [YTU30R30R](#)

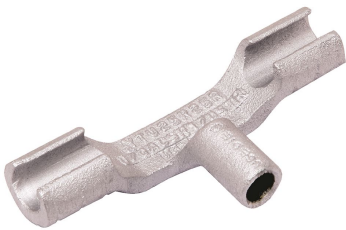

Al Compression T-Tap Connector, 266.8 kcmil ACSR, 300 - 250 kcmil Cu/Al (Run & Tap)

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	250 kcmil-300 kcmil
Conductor - Copper Str Run	250 kcmil 300 kcmil
Conductor - AL Str Run Range	266 kcmil-300 kcmil
Conductor - AL Str Run	266 kcmil 300 kcmil
Conductor - AL Str Tap Range	266 kcmil-300 kcmil
Conductor - AL Str Tap	266 kcmil 300 kcmil
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-266.8 (26/7) Partridge kcmil
Conductor - Copper Str Tap Range	250 kcmil(12,19,37 STR)-300 kcmil(19,37 STR)
Conductor - Copper Str Tap	250 kcmil(12,19,37 STR), 300 kcmil(19,37 STR)
Conductor - ACSR Str Run	266.8 (18/1) Waxwing kcmil 266.8 (26/7) Owl kcmil 266.8 (26/7) Partridge kcmil
Conductor - ACSR Str Tap Range	266.8 (18/1) Waxwing kcmil-266.8 (26/7) Owl kcmil
Conductor - ACSR Str Tap	266.8 (18/1) Waxwing kcmil 266.8 (26/7) Owl kcmil

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	110 mm
Dimension - Height inch	4.32 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	222 mm
Dimension - B Length inch	2.67 in
Dimension - Length Overall inch	8.75 in

General

Plated	N
Die Index Run Side	M
UPC	781810155608
Die Index Tap Side	M
Prefilled Oxide Inhibitor	Y
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810155608
UPC 14 Digit GTIN	00781810155608

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)