




YTU321R25R, Aluminum T-Tap Connector

By Burndy
Catalog # [YTU321R25R](#)

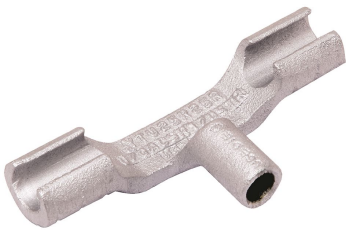

Al Compression T-Tap Connector, 300 - 336.4 kcmil
ACSR,6201,5005, 350 - 336.4 kcmil Al, 350 kcmil Cu(Run), 1/0
AWG ACSR/Al/Cu(Tap)

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run	350 kcmil
Conductor - AL Str Run Range	336.4 kcmil-350 kcmil
Conductor - AL Str Run	350 kcmil, 336.4 kcmil
Conductor - AL Str Tap	1/0 AWG(7,19 STR)
Conductor - ACSR Str Run Range	300 kcmil-336.4 kcmil
Conductor - Copper Str Tap	1/0 AWG(7,19,12 STR)
Conductor - ACSR Str Run	336.4 kcmil, 300 kcmil
Conductor - ACSR Str Tap	1/0 AWG(6-1 STR)

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	84 mm

Dimension - Height inch	3.81 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	180 mm
Dimension - B Length inch	2.09 in
Dimension - Length Overall inch	7.09 in

General

Plated	N
UPC	781810298404
Prefilled Oxide Inhibitor	Y
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810298404
UPC 14 Digit GTIN	00781810298404

Logistics

Minimum Pack Quantity	6
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)