




YTU321R28R, 1-piece Heavy-Wall Aluminum Tap Connector

By Burndy
Catalog # [YTU321R28R](#)

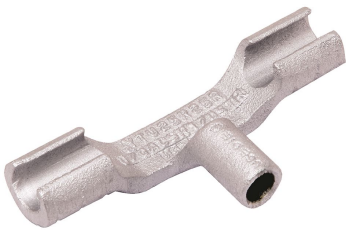

1-piece heavy wall AL compression tap connector for secondary service drop and transformer tap to primary or secondary, 8-3/5 IN L

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Dimension - Height mm	90 mm
Dimension - Height inch	3.56 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	218 mm
Dimension - B Length inch	2.00 in
Dimension - Length Overall inch	8.59 in

Conductor

Conductor - Copper Str Run	350 kcmil
Conductor - AL Str Run Range	336 kcmil-350 kcmil
Conductor - AL Str Run	336 kcmil 350 kcmil
Conductor - AL Str Tap	4/0 AWG
Conductor - ACSR Str Run Range	300.0 (26/7) Ostrich kcmil-336.4 (18/1) Merlin kcmil
Conductor - Copper Str Tap	4/0 AWG
Conductor - ACSR Str Run	300.0 (26/7) Ostrich kcmil 336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap	4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap	4/0 (6/1) Penguin AWG

General

Plated	N
Die Index Run Side	M
UPC	781810155752
Die Index Tap Side	M
Prefilled Oxide Inhibitor	Y
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810155752
UPC 14 Digit GTIN	00781810155752

Configuration

Connector Type	Tap
----------------	-----

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Dimensions

Package Height	0.000 in
----------------	----------

Product Assets

[Catalog \[English\]](#)