




YTU321R321R, 1-piece Heavy-Wall Aluminum Tap Connector

By Burndy
Catalog # [YTU321R321R](#)

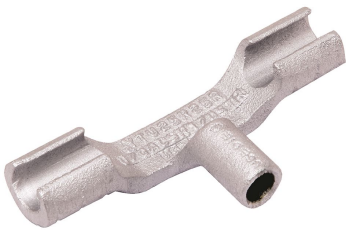

1-piece heavy wall AL compression tap connector for secondary service drop and transformer tap to primary or secondary, Die index: M

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run	350 kcmil
Conductor - AL Str Run Range	336.4 kcmil-350 kcmil
Conductor - AL Str Run	350 kcmil, 336.4 kcmil
Conductor - AL Str Tap Range	336.4 kcmil(19,37 STR)-350 kcmil(19,37 STR)
Conductor - AL Str Tap	350 kcmil(19,37 STR), 336.4 kcmil(19,37 STR)
Conductor - ACSR Str Run Range	300 kcmil-336.4 kcmil
Conductor - Copper Str Tap	350 kcmil(19,37 STR)
Conductor - ACSR Str Run	336.4 kcmil, 300 kcmil
Conductor - ACSR Str Tap Range	336.4 kcmil(18-1 STR)-300 kcmil(26-7 STR)
Conductor - ACSR Str Tap	336.4 kcmil(18-1 STR), 300 kcmil(26-7 STR)

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	111 mm
Dimension - Height inch	4.36 in
Dimension - Height fraction	4-1/3 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	222 mm
Dimension - B Length inch	2.71 in
Dimension - Length Overall inch	8.75 in

General

Plated	N
Die Index Run Side	M
UPC	781810155806
Die Index Tap Side	M
Prefilled Oxide Inhibitor	Y
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810155806
UPC 14 Digit GTIN	00781810155806

Logistics

Minimum Pack Quantity	5
Pallet Quantity	1050
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)