


# YTU33R28R, 1-piece Heavy-Wall Aluminum Tap Connector

By Burndy  
Catalog # [YTU33R28R](#)

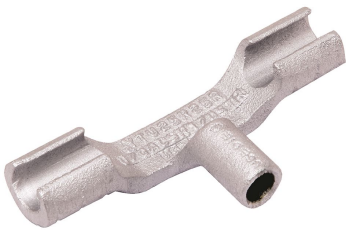

1-piece heavy wall AL compression tap connector for secondary service drop and transformer tap to primary or secondary, 8-5/8 IN L

### Specifications

|                                    |    |
|------------------------------------|----|
| Certification - ETL                | No |
| Certification - UL Recognized      | No |
| Standards - RoHS Compliance Status | CM |
| Certification - cULus              | No |
| UL Listed                          | No |
| Certification - CSA Approved       | No |

|                                 |           |
|---------------------------------|-----------|
| Dimension - Height inch         | 4 in      |
| Package Weight                  | 0.000 lb. |
| Package Length                  | 0.000 in  |
| Package Width                   | 0.000 in  |
| Dimension - L Length Overall mm | 226 mm    |
| Dimension - B Length inch       | 1.93 in   |
| Dimension - Length Overall inch | 8.89 in   |

### Conductor

|                                |                                                                                                                |
|--------------------------------|----------------------------------------------------------------------------------------------------------------|
| Conductor - Copper Str Run     | 400 kcmil                                                                                                      |
| Conductor - AL Str Run Range   | 397 kcmil-400 kcmil                                                                                            |
| Conductor - AL Str Run         | <ul style="list-style-type: none"><li>397 kcmil</li><li>400 kcmil</li></ul>                                    |
| Conductor - AL Str Tap         | 4/0 AWG                                                                                                        |
| Conductor - ACSR Str Run Range | 336.4 (30/7) Oriole kcmil-397.5 (18/1) Chickadee kcmil                                                         |
| Conductor - Copper Str Tap     | 4/0 AWG                                                                                                        |
| Conductor - ACSR Str Run       | <ul style="list-style-type: none"><li>336.4 (30/7) Oriole kcmil</li><li>397.5 (18/1) Chickadee kcmil</li></ul> |
| Conductor - ACSR Str Tap       | 4/0 (6/1) Penguin AWG                                                                                          |

### General

|                           |                |
|---------------------------|----------------|
| Plated                    | N              |
| Die Index Run Side        | M              |
| UPC                       | 781810155950   |
| Die Index Tap Side        | L              |
| Prefilled Oxide Inhibitor | Y              |
| Material                  | Aluminum Alloy |
| Plating Type              | Unplated       |
| UPC 12 Digit              | 781810155950   |
| UPC 14 Digit GTIN         | 00781810155950 |

### Configuration

|                |     |
|----------------|-----|
| Connector Type | Tap |
|----------------|-----|

### Logistics

|                       |      |
|-----------------------|------|
| Minimum Pack Quantity | 6    |
| Pallet Quantity       | 1750 |
| Carton Quantity       | 10   |

### Dimensions

|                       |          |
|-----------------------|----------|
| Package Height        | 0.000 in |
| Dimension - Height mm | 101 mm   |

### Product Assets

[Catalog \[English\]](#)