




Z2MLDN620, Copper - Multiple Outlet Connector (Mole)

By Burndy
Catalog # [Z2MLDN620](#)

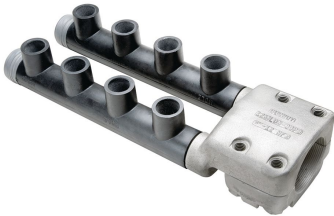

MOLE Stud Connector, 2000 Amps Capacity, 6 Outlets, #6 Str - 600 kcmil, 1-1/2" Stud Dia.

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	6 AWG-600 kcmil
Conductor - Copper Str Size	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil

Configuration

Number Of Outlets	6
Connector Type	Stud Connector

Dimensions

Dimension - Height inch	3
Dimension - B Length fraction	2-11/16 in
Dimension - Width inch	5.19
Diameter - Stud	1.5 in
Dimension - B Length inch	2.69 in
Dimension - Width fraction	3 in
Dimension - Threads per inch	12
Dimension - Length Overall inch	14 in

General

Plated	Y
Insulation Type	Diatex
UPC	781810017333
Insulation	Y
Material	Copper Alloy
Plating Type	Tin - Electro Plated
UPC 12 Digit	781810017333
UPC 14 Digit GTIN	00781810017333

Logistics

Minimum Pack Quantity	1
Pallet Quantity	90
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)