




ZMDN625, Stud Mole Assembly

By Burndy
Catalog # [ZMDN625](#)

STUD MOLE ASSY

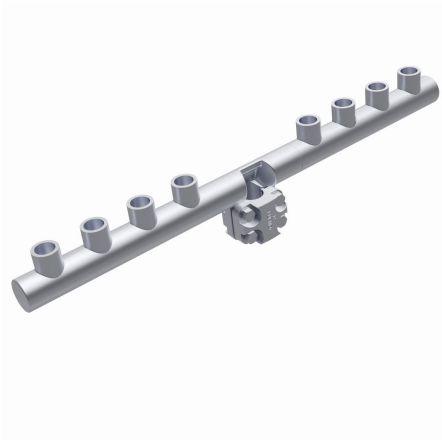

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	6 AWG-600 kcmil
Conductor - Copper Str Size	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil

Configuration

Number Of Outlets	6
Connector Type	Mole

Dimensions

Dimension - Pad Width inch	3.5 in
Dimension - Height inch	8.63 in
Dimension - Height fraction	8-5/8 in
Dimension - B Length fraction	3-1/4 in
Dimension - Width inch	3.44 in
Dimension - B Length inch	3.25 in
Dimension - Length Overall inch	22 in

General

Insulation Type	Diatex
UPC	781810056684
Insulation	Y
Material	Diatex
UPC 12 Digit	781810056684
UPC 14 Digit GTIN	00781810056684

Logistics

Minimum Pack Quantity	3
Pallet Quantity	35
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)



A Hubbell brand