

STAINLESS STEEL CLAMPS (Type 316SS)

Clamp Backs	
Trade Size	Part Number
½"	S60500CB00
¾"	S60700CB00
1"	S61000CB00





Clamp Back Spacers		
Trade Size	Description	Part Number
½" - 1"	Universal Clamp Back Spacer	S60510CBSP



STAINLESS STEEL STRAPS AND HANGERS (Type 316SS)

2-Hole Straps		(Also Available in SS EMT)			
Trade Size	A	B	C	Bolt Hole	Part Number
½"	2.427"	0.627"	1.840"	¼"	S605002S00
¾"	2.925"	0.750"	1.050"	¼"	S607002S00
1"	3.580"	0.750"	1.300"	¼"	S610002S00
1 ¼"	4.440"	0.875"	1.660"	¼"	S612002S00
1 ½"	4.440"	1.240"	1.900"	¼"	S615002S00
2"	5.290"	1.245"	2.370"	¼"	S620002S00
2 ½"	6.250"	1.250"	2.874"	¼"	S625002S00
3"	7.190"	1.250"	3.500"	¼"	S630002S00
4"	9.750"	1.250"	4.500"	¼"	S640002S00

1-Hole Straps		(Also Available in SS EMT)			
Trade Size	A	B	C	Bolt Hole	Part Number
½"	0.750"	0.060"	0.840"	¼"	S605001S00
¾"	0.750"	0.080"	1.050"	¼"	S607001S00
1"	0.750"	0.080"	1.300"	¼"	S610001S00
1 ¼"	0.875"	0.100"	1.660"	½"	S612001S00
1 ½"	0.880"	0.125"	1.900"	½"	S615001S00
2"	0.880"	0.125"	2.370"	¾"	S620001S00
2 ½"	1.250"	0.190"	2.874"	¾"	S625001S00
3"	1.250"	0.190"	3.500"	¾"	S630001S00
4"	1.250"	0.190"	4.500"	¾"	S640001S00

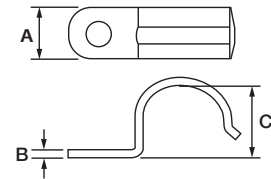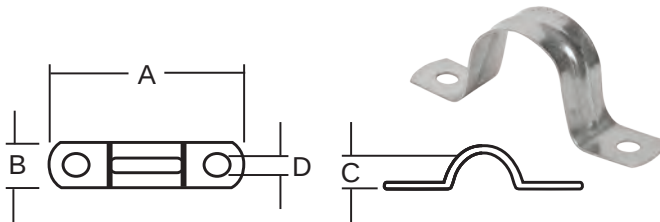

Conduit Hangers		(Also Available in SS EMT)	
Trade Size	Part Number		
½"	S60500MH00		
¾"	S60700MH00		
1"	S61000MH00		
1 ¼"	S61200MH00		
1 ½"	S61500MH00		
2"	S62000MH00		
2 ½"	S62500MH00		
3"	S63000MH00		
4"	S64000MH00		

