


# Model LS

Optional "Tea Cup" Pipe Carrier Lifting Sling 

**Product Features:**

- Standard 5'L options in stock
- Other lengths available, 3"L minimum

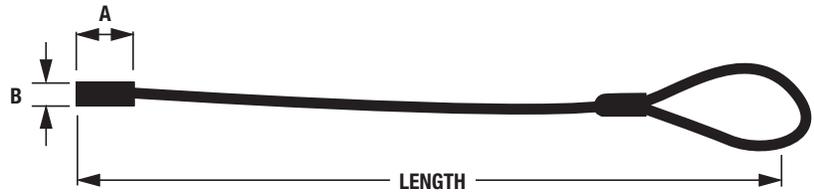

Use With	Model Number	Rated Capacity (tons)	Sling Dia. (in.)	Standard Length* (ft.)	After Swage (in.)		Wt. (lbs.)
					A	B	
PC-3/4	LS-3/4	4.9	3/4	5	3.25	1.55	9
	LS-7/8	6.6	7/8	5	3.86	1.80	14
PC-1	LS-1	8.5	1	5	4.36	2.05	19
	LS-1 1/8	10	1 1/8	5	4.81	2.30	26
	LS-1 1/4	13	1 1/4	5	5.42	2.56	33
PC-1 1/2	LS-1 1/2	18	1 1/2	5	6.52	3.00	52

\*Other sizes available 3' minimum length.  
**In Stock** - Items with green model numbers ship in 48 hours, excluding weekends and holidays.


# Model PH

Pipe Hooks 

Simplicity personified! Just attach a shackle to the lifting point, slide the "mouth" over the end of the pipe, and you're ready to lift.

**Product Features:**

- Designed for lifting and carrying steel or cast iron pipe
- Complies with ASME standards

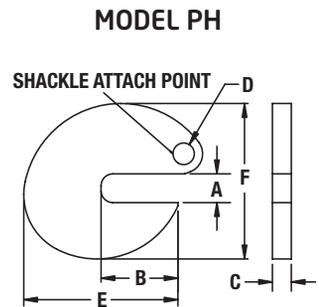

**NOTE:** Rated capacity is per pair.





**WARNING**

Use only in pairs.

Model Number Per Pair	Rated Capacity (tons) Per Pair	Shackle Pin Diameter (in.)	Bolt Type Anchor Shackle Capacity (tons)	Dimensions (inches)						Weight Per Pair (lbs.)
				A	B	C	D	E	F	
PH 1	2	5/8	2	1.50	1.84	.63	.69	3.75	5.24	7
PH 2	4	3/4	3.25	1.50	2.61	.75	.81	5.69	6.76	13
PH 4	8	1	6.5	1.50	3.86	1	1.06	7.75	7.79	23
PH 5	10	1-1/8	8.5	1.50	4.06	1.25	1.19	8.15	8.93	38
PH 7.5	15	1-3/8	12	1.50	4.06	1.75	1.44	8.15	8.93	56

Custom designed sizes available for larger capacities and other material types.  
**In Stock** - Items with green model numbers ship in 48 hours, excluding weekends and holidays.

## PRODUCT OPERATION

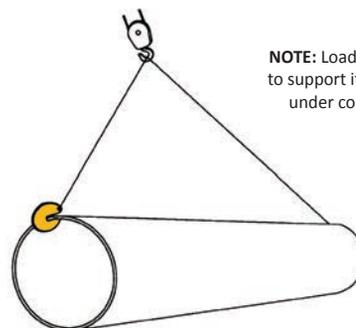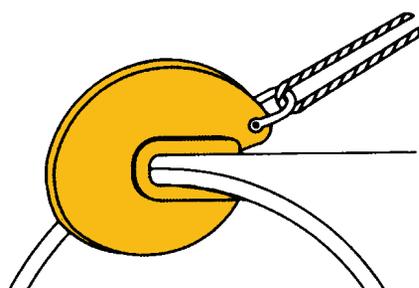

**NOTE:** Load must be able to support its own weight under compression.