



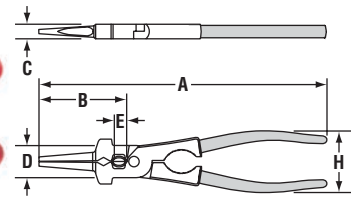


CODE BLUE® PLIERS

Features

- Professional welder's pliers
- HLT**™ Xtreme Leverage Technology
- Grooved nose easily removes spatter, grips and draws out wire.
- Installs and removes tips, nozzles, and insulation bushings.
- Coiled spring
- Hammer
- Pince de soudeur professionnel
- Xtreme Leverage Technology
- L'embout rainuré enlève facilement les éclaboussures, saisit et retire les fils métalliques.
- Il permet d'installer et de retirer les embouts, les buses, et les bagues d'isolation.
- Ressort à enroulement
- Marteau
- Alicates de soldador profesional
- Xtreme Leverage Technology
- Nariz ranurada que elimina fácilmente salpicaduras, agarra y extrae cable.
- Instala y quita puntas, boquillas y bujes de aislamiento.
- Resorte
- Martillo

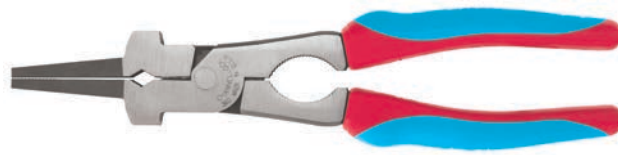

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		F NOSE WIDTH		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
360CB	9.00	228.60	2.72	69.04	0.45	11.43	1.50	38.10	0.39	9.93	0.30	7.49	2.00	50.80	0.74	334.75

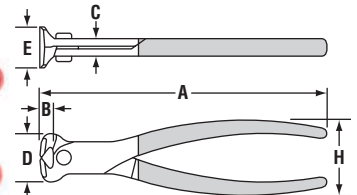


PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
358CB	8.50	215.90	0.38	9.65	0.45	11.43	1.36	35.54	1.06	26.92	2.15	54.61	0.66	300.50

Features

- End cutting plier
- HLT**™ Xtreme Leverage Technology
- Slimmer, lighter, better balanced design.
- Pinces coupantes en bout
- Xtreme Leverage Technology
- Modèle mieux équilibré, plus léger, plus mince.
- Alicates de corte frontal
- Xtreme Leverage Technology
- Diseño más ligero y equilibrado.

Features


- Improved alloy steel construction
- Cable cutter
- Cuts up to 4/0 aluminum and 2/0 copper
- Not for steel or ACSR
- Construction améliorée en acier allié
- Coupe-câble
- Coupe jusqu'à des épaisseurs d'aluminium de 4/0 et de cuivre de 2/0
- Ne coupe pas l'acier ou l'alu-acier
- Hechas de acero aleado mejorado
- Cortador de cables
- Corta aluminio de hasta 4/0 y cobre de hasta 2/0
- Herramienta no adecuada para ACSR

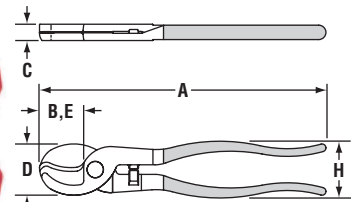

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
911CB	9.38	238.25	1.40	35.56	0.51	12.95	1.61	40.89	1.40	35.56	2.00	50.80	0.90	408.23

Features


- Crimps and cuts insulated and non-insulated solderless connections and terminals.
- Cuts 10-22 AWG wire
- Sertit et coupe les connexions et les bornes isolées et non-isolées sans soudure.
- Coupe des fils de calibre 10 à 22 AWG
- Poncha y corta conexiones y terminales sin soldadura ambas aisladas y no aisladas.
- Corta cables 10-22 AWG

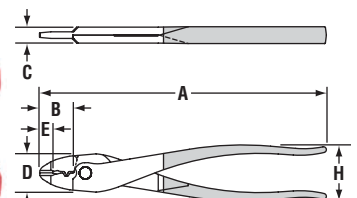

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
909CB	9.38	238.25	1.16	29.46	0.48	12.19	1.32	33.53	0.43	10.92	2.13	54.10	0.94	426.38

Features

- HLT**™ Xtreme Leverage Technology
- Crosshatch jaws for maximum grip
- Pipe grip design accommodates many shapes
- Cuts hard and soft wire
- Xtreme Leverage Technology
- Mâchoires à hachures croisées pour une prise maximum
- La conception serre-tube s'adapte à de nombreuses formes
- Coupe les fils durs et mous
- Xtreme Leverage Technology
- Mordazas reticuladas para lograr una sujeción máxima
- Diseño de empuñadura de tuberías que se adapta a muchas formas
- Corta cable duro y blando.

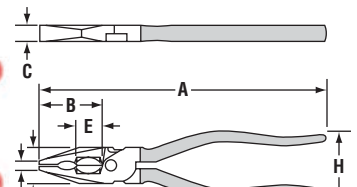

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		F NOSE WIDTH		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
348CB	8.07	204.98	1.77	44.93	0.45	11.43	1.00	25.40	0.71	17.81	0.26	6.48	2.18	55.37	0.60	272.16