

Deck-mounted manual sink faucet

Series: 2200

- 2-3/4" high cast brass spout
- Single hole or 4" cover plate
- Choice of 0.5 or 2.2 GPM flow rates



Single Hole

Model	Cartridge	Handle	Outlet
2200-ABCP	Ceramic	2200-225K	E12
2200-E2805ABCP	Ceramic	2200-225K	E2805

4" Cover Plate


Model	Cartridge	Handle	Outlet
2200-4ABCP	Ceramic	2200-225K	E12
2200-4E2805ABCP	Ceramic	2200-225K	E2805
2201-4ABCP*	Ceramic	2200-225K	E12


*With pop-up drain assembly.

Cartridge

Model	Description
1	Ceramic
	2300-X With volume control and hot water limit stop


Handle

Model	Description
2 2200-225K	2-3/4" lever handle 

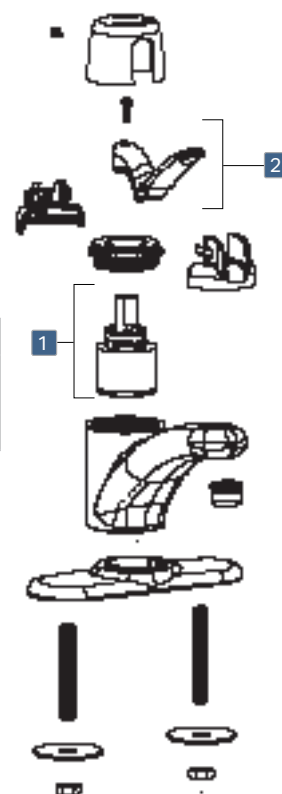

Spout Dimensions

Model	A	B	C	Outlet
2200-4	3"	4-3/4"	6-3/8"	Female

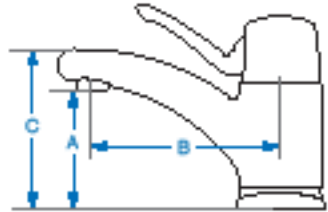

Outlets

Model	Thread	GPM
Aerated Standard		
E12	13/16" - 27 UNS Male	2.2
Non-Aerated Spray Vandal Resistant		
E2805	13/16" - 27 UNS Male	0.5

