


Deck-mounted metering sink faucet Series: 333

- 1/2" NPSM supply inlets and coupling nut for 3/8" or 1/2" flexible riser
- MVP™ metering cartridge
- Polished chrome finish



Model	Cartridge	Handle	Outlet
333-336PSHABCP	NAIAD	336	E12
333-665E39VPSHABCP	MVP	665	E39VP
333-665PSHABCP	MVP	665	E12
333-665PSHVPAABCP	MVP	665	E12VP
333-E2805-665PSHAB	MVP	665	E2805

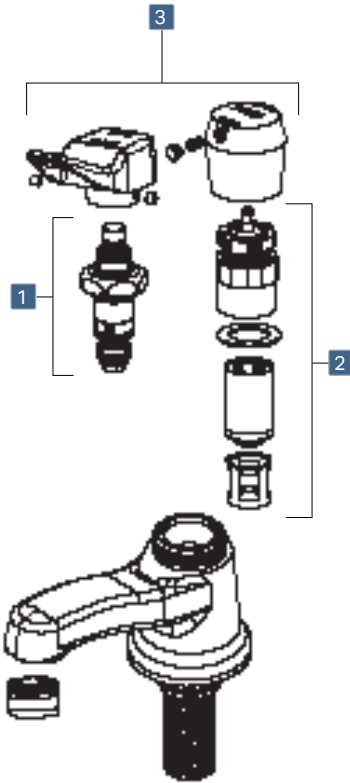


Cartridges

Model	Description
1	NAIAD
	335-X Adjustable metering cartridge
2	MVP
	667-080K MVP cartridge and actuator

Handles

Model	Description	
3	336 2-13/16" push-tilt handle	
	665 1-3/4" MVP metering push handle	

Spout Dimensions

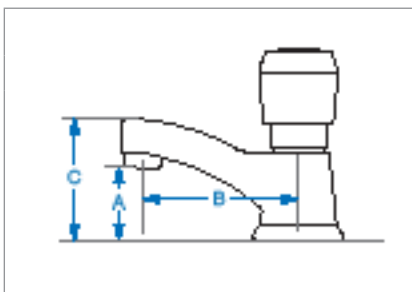

Model	A	B	C	Outlet
333	1-1/2"	3-1/2"	2-5/8"	Female

Outlets

Model	Thread	GPM
Aerated Standard		
E12	13/16" - 27 UNS Male	2.2
Aerated Vandal Resistant		
E12VP	13/16" - 27 UNS Male	2.2
Non-Aerated Spray Vandal Resistant		
E39VP	13/16" - 27 UNS Male	0.35
E2805	13/16" - 27 UNS Male	0.5