


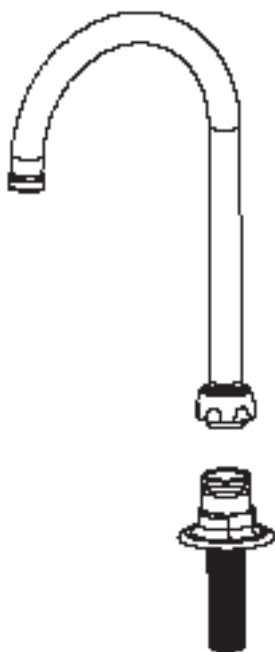

Remote spout


Series: 626, 629

- Single hole
- Choice of wall or deck mount
- Gooseneck design
- Available with laminar flow control spout insert
- Polished chrome finish



Model	Mount	Outlet	Spout
626-ABCP	Deck	-	GN2
626-E3ABCP	Deck	E3	GN2A
626-FCABCP	Deck	-	GN2FC
626-GN8FCABCP	Deck	-	GN8FC
629-E3ABCP	Wall	E3	GN1A

Spouts

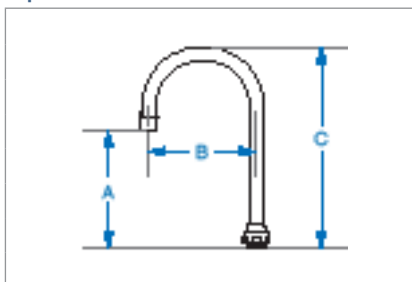

Model	A	B	C	Outlet
Gooseneck Rigid/Swing				
GN1A	5-7/8"	3-1/2"	8-3/8"	Male
GN2	5-5/8"	5-1/4"	9-3/4"	Plain
GN2A	6-1/8"	5-1/4"	9-3/4"	Male
Gooseneck 1.5 GPM Laminar Insert				
GN2FC	6-1/8"	5-1/4"	9-3/4"	Plain
GN8FC	6-1/8"	8"	11-1/4"	Plain

Outlets

Model	Thread	GPM
Aerated Standard		
E3	13/16" - 24 UNS Female	2.2