


Deck-mounted manual sink faucet Series: 700, 730

- 2-5/8" high integral cast brass spout
- Single hole
- 2.2 GPM flow rate



Model	Cartridge	Handle	Outlet
700-317COLDABCP	Quaturn	317-COLD	E12
700-317HOTABCP	Quaturn	317-HOT	E12
700-COLDABCP	Quaturn	633-COLD	E12
700-COLDXKABCP	Ceramic	633-COLD	E12
730-COLDABCP	Quaturn	369-COLD	E12
730-COLDXKABCP	Ceramic	369-COLD	E12
730-HOTABCP	Quaturn	369-HOT	E12
730-HOTXKABCP	Ceramic	369-HOT	E12

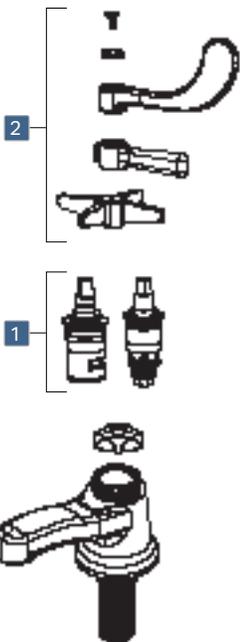

Cartridges

Model	Description
Quaturn™ Compression	
1-099XT	Short stem, cold
1-100XT	Short stem, hot
Ceramic	
1-099XK	Short stem, cold
1-100XK	Short stem, hot

Handles

Model	Description
317	4" wristblade Vandal proof
369	2-3/8" lever Vandal proof
633	3" cross

Spout Dimensions

Model	A	B	C	Outlet
700	1-1/2"	3-1/2"	2-5/8"	Female

Outlet

Model	Thread	GPM
Aerated Standard		
E12	13/16" - 27 UNS Male	2.2