


Deck-mounted manual sink faucet Series: 786

- 8" centers
- 1/2" NPSM supply inlets and coupling nut for 3/8" or 1/2" flexible riser
- MVP™ metering cartridges
- Polished chrome finish
- 2.2 GPM flow rate



Model	Cartridge	Handle	Outlet	Spout
786-E3-665ABCP	MVP	665	E3	GN2A
786-G1AE3-665AB	MVP	665	E3	GN1A

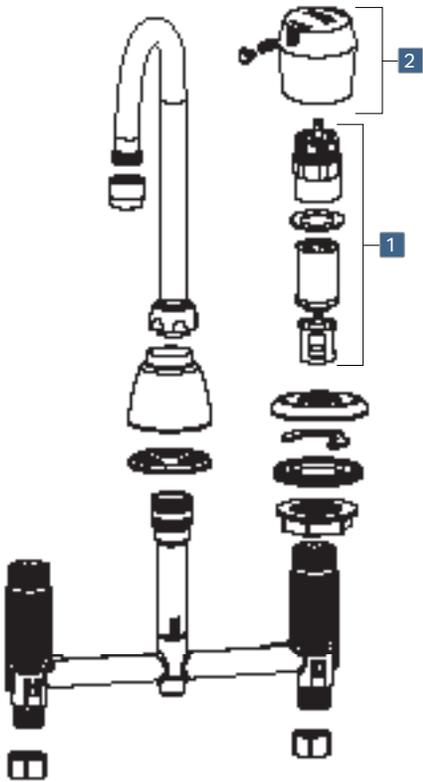

Cartridge

Model	Description
1	Metering
	667-080K MVP cartridge and actuator

Handles

Model	Description
2	1-3/4" MVP metering push handle 

Spout Dimensions

Model	A	B	C	Outlet
Gooseneck Rigid/Swing				
GN1A	5-7/8"	3-1/2"	8-3/8"	Male
GN2A	6-1/8"	5-1/4"	9-3/4"	Male

Outlet

Model	Thread	GPM
Aerated Standard		
E3	13/16" - 24 UNS Female	2.2