


Deck-mounted manual sink faucet**Series: 802**

- 4" centers
- 1/2" NPSM supply inlets and coupling nut for 3/8" or 1/2" flexible riser
- Vandal-resistant handles standard
- Ceramic or Quaturn™ compression cartridges
- Polished chrome finish

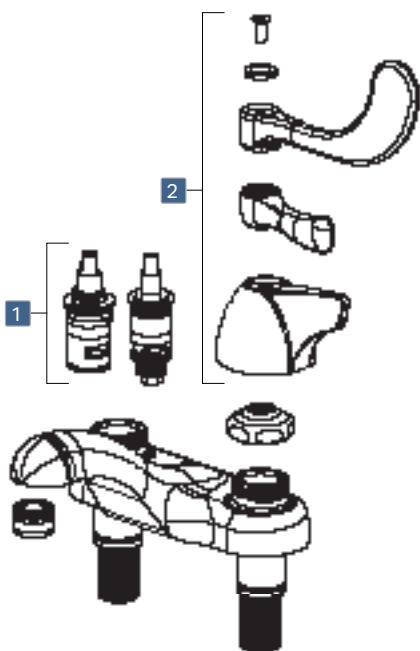


Model	Cartridge	Handle	Outlet
802-317ABCP	Quaturn	317	E12
802-317XKABCP	Ceramic	317	E12
802-V317ABCP	Quaturn	317	E12VP
802-V317XKABCP	Ceramic	317	E12VP
802-VE2805-317ABCP	Quaturn	317	E2805
802-ABCP	Quaturn	390	E12
802-XKABCP	Ceramic	390	E12
802-VABCP	Quaturn	390	E12VP
802-VXKABCP	Ceramic	390	E12VP
802-VE2805ABCP	Quaturn	390	E2805
802-1000ABCP	Quaturn	1000	E12
802-1000XKABCP	Ceramic	1000	E12
802-V1000ABCP	Quaturn	1000	E12VP
802-VE2805-1000AB	Quaturn	1000	E2805
802-LEHAB	Quaturn	–	E12
802-LEHXXAB	Ceramic	–	E12
802-VLEHAB	Quaturn	–	E12VP

**Cartridges**

Model	Description
1	Quaturn™ Compression
	1-099XT Short stem, right
	1-100XT Short stem, left
	Ceramic
	1-099XK Short stem, right
	1-100XK Short stem, left

Handles

Model	Description
2	317 4" wristblade Vandal proof
	390 2-3/8" lever Vandal proof
	1000 2" canopy Vandal proof

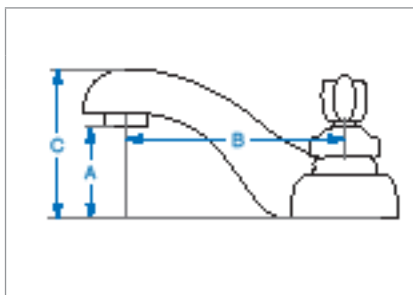Spouts

Model	A	B	C	Outlet
802	1-5/8"	4"	2-3/4"	Female

Outlets

Model	Thread	GPM
Aerated Vandal Resistant		
E12VP	13/16" - 27 UNS Male	2.2
Aerated Standard		
E12	13/16" - 27 UNS Male	2.2
Non-Aerated Spray Vandal Resistant		
E2805	13/16" - 27 UNS Male	0.5