


## Deck-mounted metering sink faucet Series: 807, 844, 857

- 1-5/8" high cast brass spout
- Single hole or 4" cover plate
- Flow rates from 0.5, 1.5, or 2.2 GPM

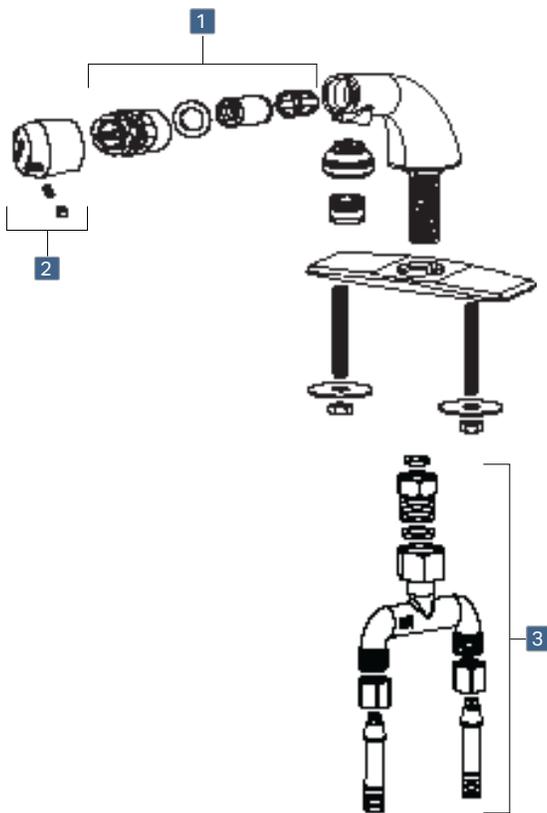

## Single Hole, Single Supply

Model	Cartridge	Handle	Outlet
807-665PSHABCP	MVP	665	E15
807-E12-665PAB	MVP	665	E12
807-E12V665PSHAB	MVP	665	E12VP
807-E2805-665PSHAB	MVP	665	E2805

## 4" Cover Plate, Single Supply

Model	Cartridge	Handle	Outlet
857-665PSHABCP	MVP	665	E15
857-E12-665PSHABCP	MVP	665	E12
857-E12V665PSHAB	MVP	665	E12VP
857-E2805-665PSHAB	MVP	665	E2805

## 4" Cover Plate, Dual Supply\*

Model	Cartridge	Handle	Outlet
844-665PSHABCP	MVP	665	E15
844-E12-665PSHABCP	MVP	665	E12

\*Includes connection assembly and inlet check tailpieces to prevent cross-flow.

## Cartridge

Model	Description
1 667-080K	MVP cartridge and actuator

## Handle


Model	Description	
2 665	1-3/4" MVP metering push handle	

## Dual Supply Connection Assembly

Model	Description
3 1-143K	Connection assembly
58-018K	Tailpiece

## Spout Dimensions

Model	A	B	C	Outlet
807	3-1/2"	4-1/4"	4-1/8"	Female

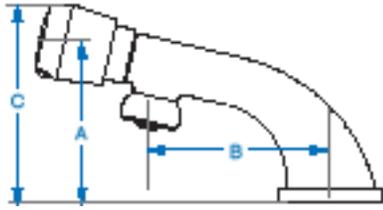

## Outlets

Model	Thread	GPM
<b>Spray</b>		
E15	13/16" - 27 UNS Male	1.5
<b>Aerated Standard</b>		
E12	13/16" - 27 UNS Male	2.2
<b>Aerated Vandal Resistant</b>		
E12VP	13/16" - 27 UNS Male	2.2
<b>Non-Aerated Spray Vandal Resistant</b>		
E2805	13/16" - 27 UNS Male	0.5