


# CHIPPING

## Accessories & Dimensions - Chipping

 


### CHISEL RETAINERS

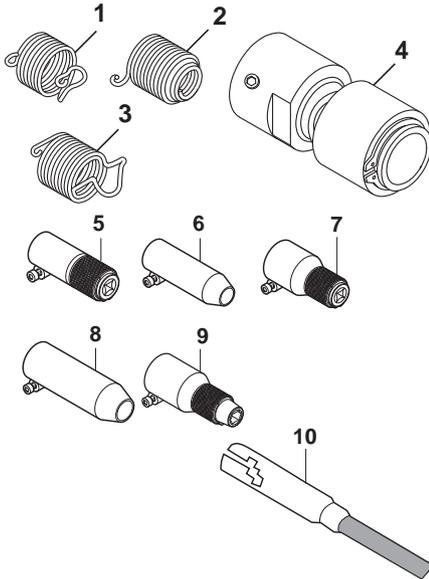


MODEL USED	TYPE	PART NUMBER	DESCRIPTION
<b>B15B(M)</b>	5	615 250 5240	1/2" Square Tool Retainer
	6	615 250 5230	Round adjustable sleeve
<b>B16B(M) / B18B(M)</b>	5	615 250 5250	1/2" Square Tool Retainer
<b>B19B(M)</b>	7	615 250 5380	1/2" Square Tool Retainer
	8	615 250 5190	Round adjustable sleeve
<b>B19B1</b>	9	615 250 5260	5/8" Hexagonal Tool Retainer
<b>B21B(M)</b>	7	615 250 5360	1/2" Square Tool Retainer
	1	205 048 7413	Quick Change
	1	A046095	Heavy Duty Quick Change
	2	A046096	Bee hive
<b>CP7111 / CP714</b>	3	205 052 5333	Zip Change
	3	A046094	Heavy Duty Zip Change made in USA
	4	894 015 8924	Posi Lock Quick Change
	4	A121721	Heavy Duty Posi Lock Quick Change made in USA
<b>CP716</b>	1	CA157640	Quick Change
<b>CP717</b>	1	A047095	Quick change retainer
	2	A047096	Bee hive
<b>CP9356</b>	10	P136983	Round Nose

### DIMENSIONS




MODEL	A	
	in.	mm
<b>B15B</b>	8	201
<b>B16B</b>	9	231
<b>B16BV</b>	16.7	425
<b>B15M</b>	13.2	335
<b>B16M</b>	14.4	366
<b>B16MV</b>	14.2	360
<b>CP0456 LASAN</b>	16.3	413
<b>CP0456 LESAR</b>	8.6	219
<b>CP0951</b>	13.4	340
<b>CP7115</b>	11.4	290
<b>CP7120</b>	18	457
<b>CP9356NS</b>	9.4	238
<b>CP9356WF</b>	9.4	238

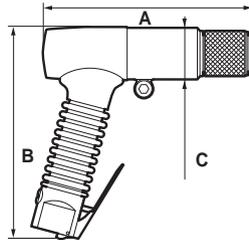

AIR SCRIBE	A	
	in.	mm
<b>CP9160</b>	5.8	127
<b>CP9361</b>	5.0	147

For B20 series dimensions, please see the specifications table p.160

PISTOL SHAPE	A		B		C	
	in	mm	in	mm	in	mm
<b>B18B</b>	6.8	173	6,7	170	1,7	43
<b>B18BV</b>	16.5	420	7	180	2	50
<b>B18M</b>	12.4	315	6,7	170	1,9	48
<b>B18MV</b>	13.4	340	7	180	2	50
<b>B19B</b>	7.5	191	7	180	2	51
<b>B19B1</b>	8.6	218	7	180	2	51
<b>B19BV</b>	17.7	450	7	180	2,3	58
<b>B19M</b>	13.5	342	6,7	177	2,4	60
<b>B19MV</b>	14.8	375	7	180	2,3	58
<b>B21B</b>	12.2	310	6,5	165	2,4	60
<b>B21M</b>	19.0	484	6,5	165	2,6	66
<b>CP0952</b>	12.6	320	-	-	2,5	64
<b>CP7111</b>	7.5	190	5,7	145	1,6	40
<b>CP7125</b>	12.4	315	4,7	120	1,7	45
<b>CP714</b>	7.7	195	6.1	155	2	50
<b>CP716</b>	7.5	190	-	-	1,6	40
<b>CP717</b>	8.7	220	6.1	155	2,4	60
<b>GV5</b>	15.2	385	-	-	-	-
<b>RA1</b>	7.5	190	5,1	130	1,2	30
<b>RA1BL</b>	7.5	190	5,1	130	1,2	30
<b>RA2C</b>	8.3	210	5,9	150	1,6	40
<b>RA2H</b>	8.3	210	5,9	150	1,6	40

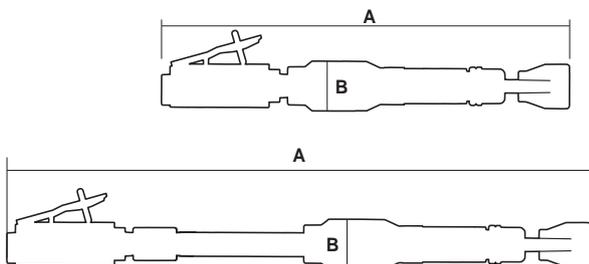

SAND RAMMERS	A		B	
	in	mm	in	mm
<b>CP0200B18-2F</b>	15.4-17.3	390-440	1.8	46
<b>CP0200B18L-2F</b>	21.3-23.3	542-592	1.8	46
<b>CP0200B22-2F</b>	18.3-20.8	465-529	2.0	50
<b>CP0200B22L-2F</b>	24.2-26.7	614-678	2.0	50
<b>CP0200B25-2F</b>	24.8-28.1	630-713	2.4	60
<b>CP0200B25L-2F</b>	40.9-44.1	1038-1121	2.4	60
<b>CP0200B32L-2F</b>	44.2-49.2	1123-1250	2.7	68