

# Type 4 Panel Enclosures

## Wall-Mount Enclosures Type 4 Single-Door with 3-Point Locking Data Sheet and Catalog Number



### Finish

- Wash and phosphate undercoat
- ANSI 61 gray polyester powder finish

### Accessories

- Panels
- Swing-out panel kit
- NEMA terminal kit
- Window Kits
- Floor stand kit
- Replacement handle, T4PKHB, (see page 427)

### Construction

- Enclosure and door are fabricated from code gauge steel, (see pages 160 & 161)
- All continuous welded seams are finished smooth
- Continuous hinge with stainless steel hinge pin
- Internal 3-point latching with a keylocking and padlock handle
- Door has a seamless poured in-place gasket
- Formed lip around enclosure opening diverts liquids and contaminants
- Ground stud provided on door and body
- Print pocket provided
- .375-16 colar studs are provided for mounting optional panel
- External mounting feet

### Application

- Houses electrical controls and instruments
- Intended for indoor or outdoor use
- Protects against windblown dust and rain, splashing water and hose directed water

### Standards

- UL 508A listed, Type 4, Type 12
- CSA C22.2 No.94 certified, Type 4, Type 12
- Conforms to NEMA standard for Type 3, Type 4, Type 12

### Discount Schedule: C2


### Subclass: DF3

| Enclosure      | Enclosure Size |                  | Gauge | Panel          | Conductive     | Panel Size    |            |
|----------------|----------------|------------------|-------|----------------|----------------|---------------|------------|
| Catalog Number | Height         | Width x Depth    |       | Catalog Number | Catalog Number | Height        | Width      |
|                | in.            | A x B x C<br>mm  |       |                |                | in.           | mm         |
| 24206-43PT     | 24 x 20 x 6    | 609 x 508 x 152  | 16    | AW2420P        | AW2420GP       | 20.87 x 16.87 | 530 x 429  |
| 24208-43PT     | 24 x 20 x 8    | 609 x 508 x 203  | 16    | AW2420P        | AW2420GP       | 20.87 x 16.87 | 530 x 429  |
| 24248-43PT     | 24 x 24 x 8    | 609 x 609 x 203  | 14    | AW2424P        | AW2424GP       | 20.87 x 20.87 | 530 x 530  |
| 30248-43PT     | 30 x 24 x 8    | 762 x 609 x 203  | 14    | AW3024P        | AW3024GP       | 26.87 x 20.87 | 682 x 530  |
| 30308-43PT     | 30 x 30 x 8    | 762 x 762 x 203  | 14    | AW3030P        | AW3030GP       | 26.87 x 26.87 | 682 x 682  |
| 36248-43PT     | 36 x 24 x 8    | 914 x 609 x 203  | 14    | AW3624P        | AW3624GP       | 32.87 x 20.87 | 835 x 530  |
| 36308-43PT     | 36 x 30 x 8    | 914 x 762 x 203  | 14    | AW3630P        | AW3630GP       | 32.87 x 26.87 | 835 x 682  |
| 48368-43PT     | 48 x 36 x 8    | 1219 x 914 x 203 | 14    | AW4836P        | AW4836GP       | 44.87 x 32.87 | 1139 x 835 |
| 242010-43PT    | 24 x 20 x 10   | 609 x 508 x 254  | 16    | AW2420P        | AW2420GP       | 20.87 x 16.87 | 530 x 429  |
| 363010-43PT    | 36 x 30 x 10   | 914 x 762 x 254  | 14    | AW3630P        | AW3630GP       | 32.87 x 26.87 | 835 x 682  |
| 483610-43PT    | 48 x 36 x 10   | 1219 x 914 x 254 | 14    | AW4836P        | AW4836GP       | 44.87 x 32.87 | 1139 x 835 |

**Notes:** We can provide special sizes, finishes and other modifications. Consult the factory for your special requirements.

Wall-Mount Enclosures  
Type 4 Single-Door with 3-Point Locking  
Illustration Sheet and Catalog Number

| Enclosure      | Enclosure Size         |                  | Gauge | Panel          | Conductive     | Panel Size     |            |
|----------------|------------------------|------------------|-------|----------------|----------------|----------------|------------|
| Catalog Number | Height x Width x Depth |                  |       | Catalog Number | Catalog Number | Height x Width | Panel      |
|                | A x B x C              |                  |       |                |                |                |            |
|                | in.                    | mm               |       |                |                | in.            | mm         |
| 242412-43PT    | 24 x 24 x 12           | 609 x 609 x 305  | 14    | AW2424P        | AW2424GP       | 20.87 x 20.87  | 530 x 530  |
| 302412-43PT    | 30 x 24 x 12           | 762 x 609 x 305  | 14    | AW3024P        | AW3024GP       | 26.87 x 20.87  | 682 x 530  |
| 363012-43PT    | 36 x 30 x 12           | 914 x 762 x 305  | 14    | AW3630P        | AW3630GP       | 32.87 x 26.87  | 835 x 682  |
| 363612-43PT    | 36 x 36 x 12           | 914 x 914 x 305  | 14    | AW3636P        | AW3636GP       | 32.87 x 32.87  | 835 x 835  |
| 483612-43PT    | 48 x 36 x 12           | 1219 x 914 x 305 | 14    | AW4836P        | AW4836GP       | 44.87 x 32.87  | 1139 x 835 |
| 603612-43PT    | 60 x 36 x 12           | 1524 x 914 x 305 | 14    | AW6036P        | AW6036GP       | 56.87 x 32.87  | 1444 x 835 |
| 483616-43PT    | 48 x 36 x 16           | 1219 x 914 x 406 | 14    | AW4836P        | AW4836GP       | 44.87 x 32.87  | 1139 x 835 |
| 603616-43PT    | 60 x 36 x 16           | 1524 x 914 x 406 | 14    | AW6036P        | AW6036GP       | 56.87 x 32.87  | 1444 x 835 |

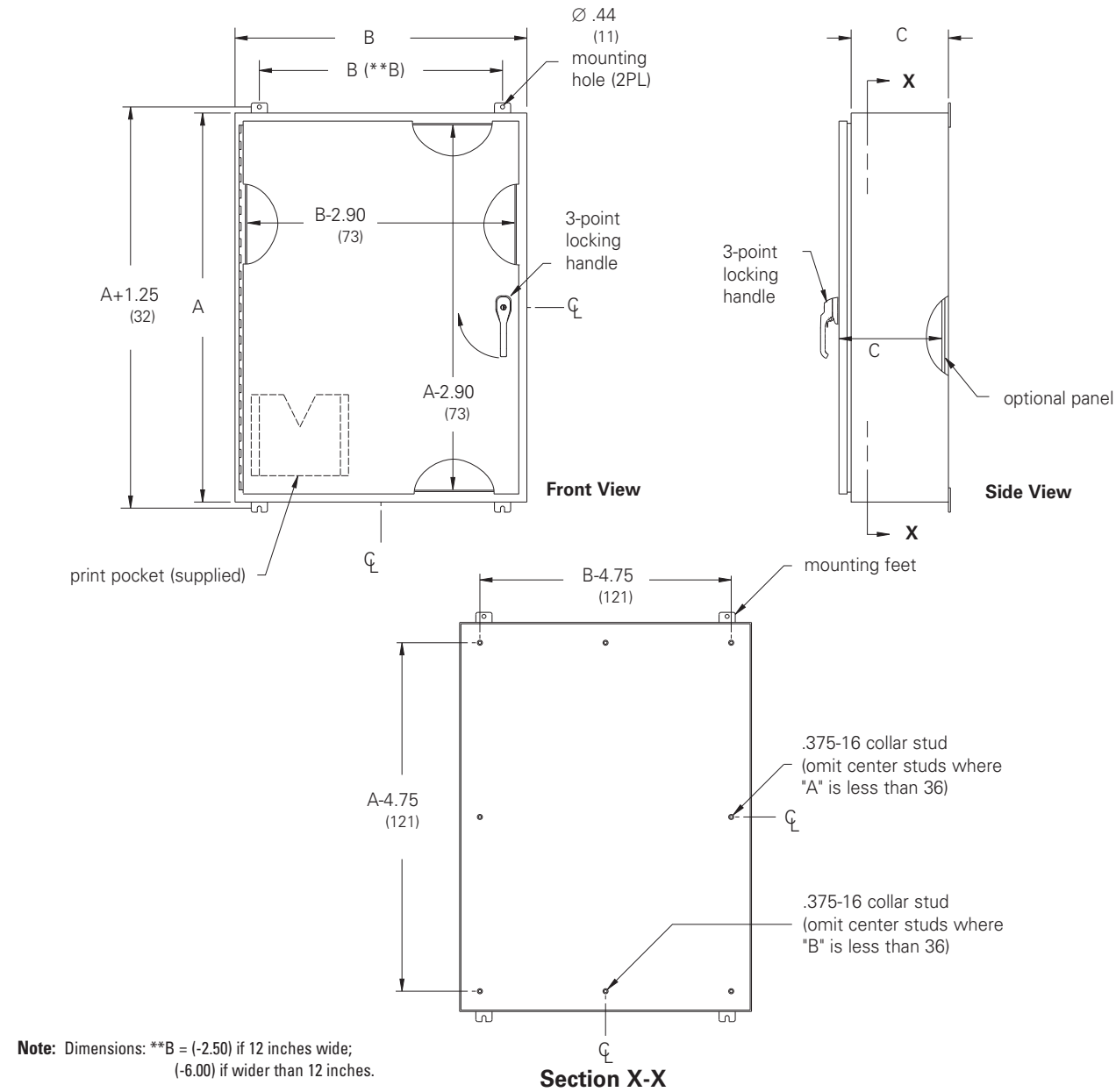

Notes: Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.