

# Type 4X Non-Metallic Enclosures

## Fiberglass Ground-Mount Enclosures Type 4X Free-Standing Double-Door Data Sheet



### Application

- Houses electrical, electronic, instrument, and mechanical controls
- Intended for indoor or outdoor use
- Ideally suited for harsh environments
- Protects against corrosion, windblown dust and rain, splashing water, and hose directed water

### Standards

- UL/cUL 50 Listed, Type 1, Type 3, Type 3R, Type 4X, Type 12
- Conforms to NEMA Standard for Type 1, Type 3, Type 3R, Type 4X, Type 12
- CSA 22.2, Type 1, Type 3, Type 3R, Type 4X, Type 12
- Temperature Range: -40°F to 250°F (040°C to 120°C)
- Flammability Rating: UL94-5V
- Self Extinguishing: Non-flame propagating
- Chemical Resistance: (see chart, pages 464 - 467)

### Finish

- Gray color

### Accessories

- Back Panels (pages 290 - 291)
- See accessories (pages 292 - 294)

### Construction

- Enclosures are an impact resistant, non-conductive, light-weight hot compression molded Non-Metallic reinforced polyester
- Poured polyurethane seamless gasket provides watertight, dust-tight environmental seal
- Twist lock latches provide ease of entry into enclosure
- 300 series stainless steel used on all external hardware
- Integral mounting bosses utilize threaded brass inserts for mounting optional panel
- Rounded edges reduce build-up of dust and debris
- Full length stainless steel hinged cover
- Built in padlock hasp provide optional secure closure locking (padlock not included)

### Discount Schedule: F2


### Subclass: G00

**Notes:** We can provide special modifications. Consult the factory for your special requirements.


## Fiberglass Ground-Mount Enclosures Type 4X Free-Standing Double-Door Illustration Sheet and Catalog Number

Enclosure Catalog #	Overall Dimensions		Inside Dimensions		Dimensions						Panel Number								
	H x W x D		A x B x C		J		K		L			Enclosure Opening							
	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm		in.	mm						
724818-4XFFSD	72.5	58.5 x 19.38	1841	1232 x 492	72.0	48.0 x 18.88	1829	1219 x 476	17.88	454	15.50	388	19.50	495	64.75	1645	20.50	521	*AWF7221
727218-4XFFSD	72.5	72.5 x 19.38	1841	1842 x 492	72.0	72.0 x 18.88	1829	1829 x 479	17.88	454	15.50	388	31.50	800	64.75	1645	32.50	826	*AWF7233


\* When ordering panels, the part number includes only one (1) panel - two (2) are required

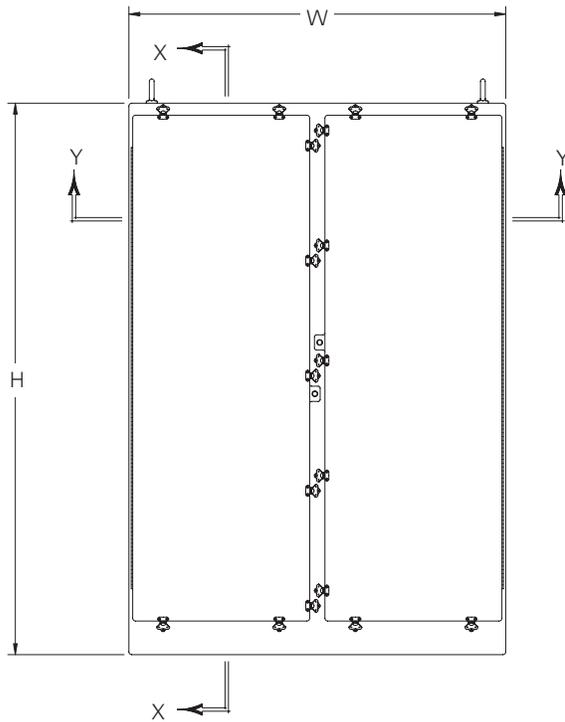

Front View

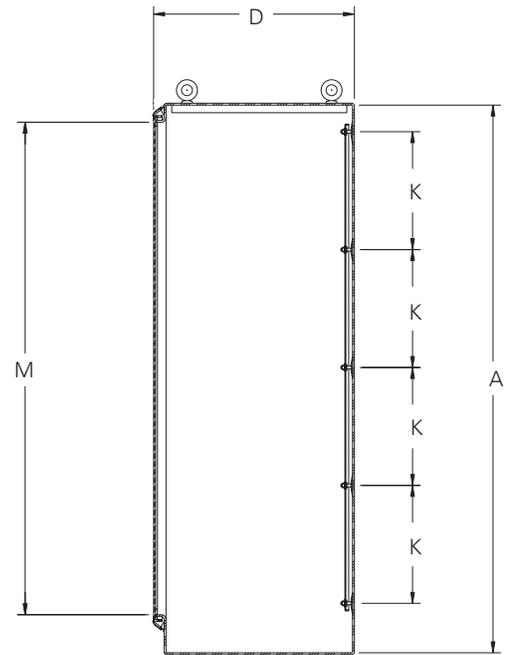

Section X-X

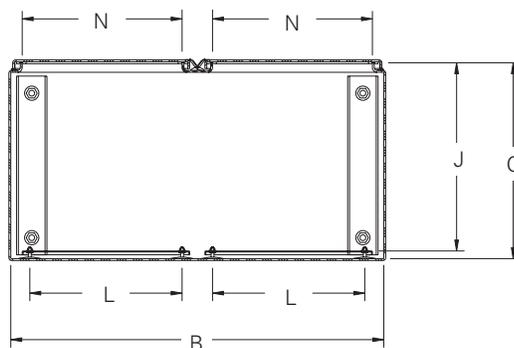

Section Y-Y

### Panel Finishes

Example: AW108\_\_

Insert for \_\_

P = Carbon Steel  
SP = Stainless Steel  
AP = Aluminum

Notes: Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.