


B156 - B161 Two Hole Closed Angle

- Standard finishes: ZN, GRN


Part No.	A	Wt./C	
		Lbs.	kg
B156	82½°	56	(25.4)
B157	75°		
B158	67½°		
B159	60°		
B160	52½°		
B161	37½°		

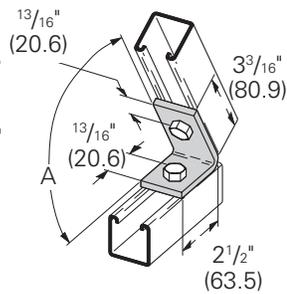

B155 Two Hole Closed Angle

- Standard finishes: ZN, GRN, HDG, SS4
- Wt./C 63 Lbs. (28.6 kg)


PA ^{ZN}_{GRN}

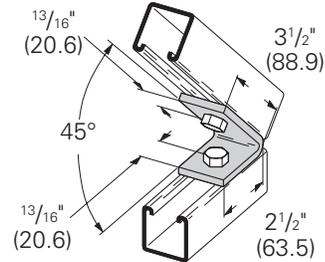

B363 - B369 Four Hole Closed Angle


- Standard finishes: ZN, GRN

Part No.	A	Wt./C	
		Lbs.	kg
B363	82½°	95	(43.1)
B364	75°		
B365	67½°		
B366	60°		
B367	52½°		
B368	45°		
B369	37½°		

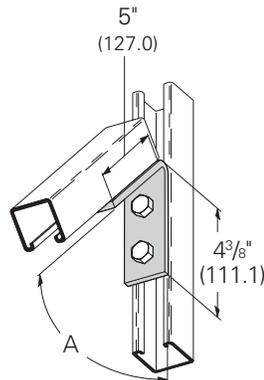

B335-2 SERIES Three Hole Adjustable Hinge


- Standard finishes: ZN, GRN

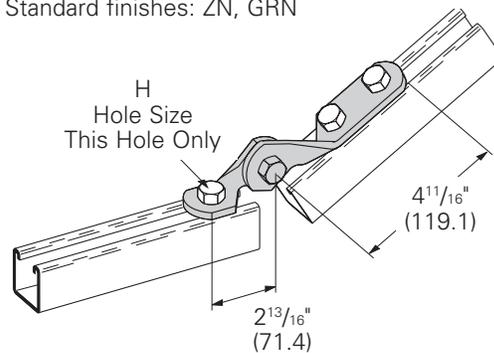

Part No. & Size	Hole Size H		Wt./C	
	In.	mm	Lbs.	kg
B335-2-3/8	7/16"	(11.1)	96	(43.2)
B335-2-1/2	9/16"	(14.3)	94	(42.3)
B335-2-5/8	11/16"	(17.4)	92	(41.4)
B335-2-3/4	13/16"	(20.6)	90	(40.5)

B335 Four Hole Adjustable Hinge


- Standard finishes: ZN, GRN
- Wt./C 110 Lbs. (49.9 kg)

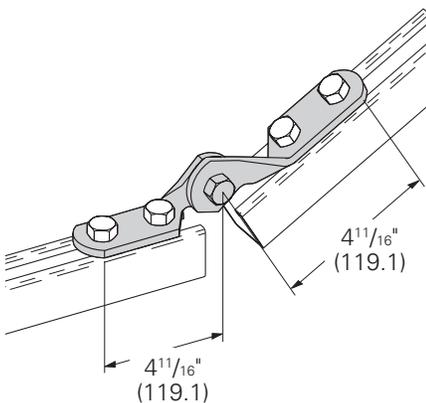

B335V Three Hole Half Hinge


- Standard finishes: ZN, GRN

Part No. & Size	Hole Size H		Wt./C	
	In.	mm	Lbs.	kg
B335V-1/2	9/16"	(14.3)	53	(24.1)
B335V-5/8	11/16"	(17.4)	54	(24.5)
B335V-3/4	13/16"	(20.6)	55	(24.9)

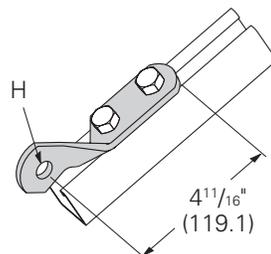

B335-1 Two Hole Adjustable Hinge

- Standard finishes: ZN, GRN
- Wt./C 78 Lbs. (35.4 kg)

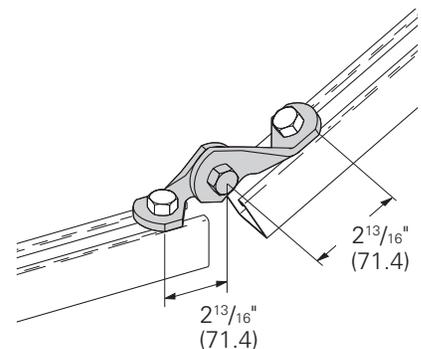

PA Pre-assembled fitting

Reference page 106 for general fitting and standard finish specifications.