

B823 Profile End Caps

- Material: Polyvinyl Chloride (PVC/Vinyl)
- Withstands intermittent temperatures up to 350°F (177°C) and 200°F (93°C) continuous
- Available in colors: White (W), Yellow (Y), Black (BLK), Gray (GRY), Green (GRN)




Approx. $\frac{3}{4}$ " deep
(19.0)

Part No.	Fits Channel Sizes	Wt./C Lbs. kg
B823-22A	B22A, B24A, B26A	6.9 (3.1)
B823-22	B22, B24, B26	4.1 (1.8)
B823-42	B42	3.8 (1.7)
B823-52	B52, B54, B56	3.5 (1.6)

B825 Plastic End Caps



- Material: Polyurethane
- Available in colors: Gray (GRY), Green (GRN)

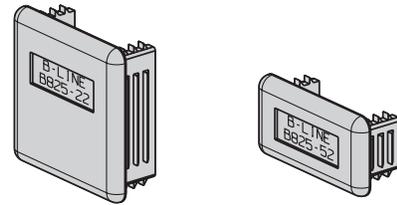

Part No.	Fits Channel Sizes	Wt./C Lbs. kg
B825-22	B22 & B24	2.0 (0.9)
B825-52	B52 & B54	1.0 (0.4)

B408SLBVNS Series Stand-Off Brackets

- Material: $\frac{1}{4}$ " (6.3)
- Standard Finishes: HDG, ZN, GRN
- For pipe or rigid conduit sizes of $1\frac{1}{2}$ " (40) and 2" (50) use with B501 Series 'U'-Bolts (see page 53)
- For strut channels $1\frac{5}{8}$ " (41.3) wide use with B500 Series Square 'U'-Bolts (see page 53)
- Hardware is not included

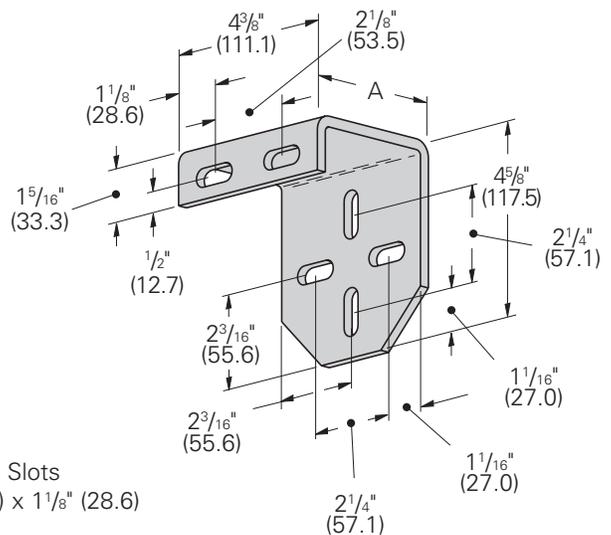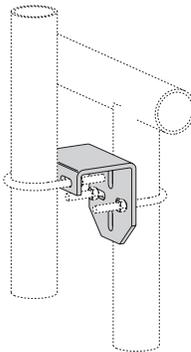

Part No.	A In. (mm)	Wt./C Lbs. kg
B408SLBVNS	$3\frac{1}{2}$ " (88.9)	189 (85.7)
B408SLBVNS1	3" (76.2)	220 (99.8)
B408SLBVNS2	2" (50.8)	236 (107.0)

Reference page 106 for general fitting and standard finish specifications.