


Fiberglass

BFP2400 Series 2-Hole Pipe Clamps


- Design Load Safety Factor of 3
- Material: Glass reinforced polyester

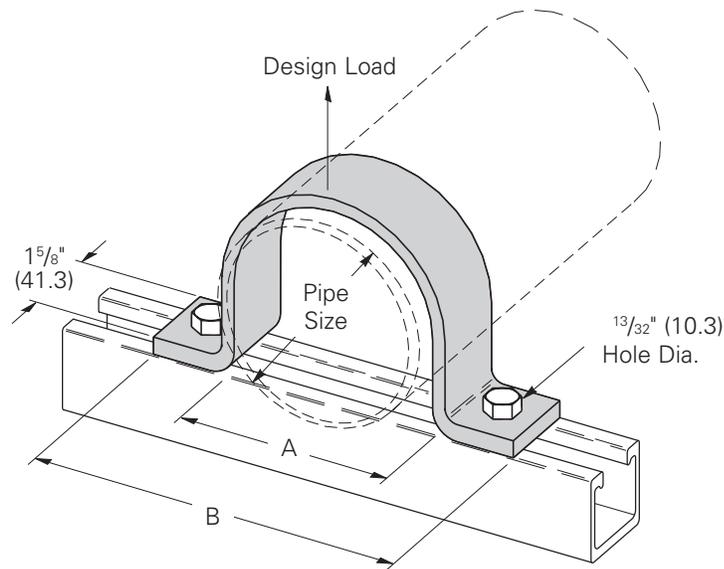

Part No.	Nominal Pipe Size		A		B		Design Load	
	in.	mm	in.	mm	in.	mm	Lbs.	kN
BFP2400-2	2	(50)	2 ³ / ₈	(60)	5 ¹ / ₂	(140)	115	(0.51)
BFP2400-3	3	(80)	3 ¹ / ₂	(89)	6 ³ / ₄	(171)	130	(0.58)
BFP2400-4	4	(100)	4 ¹ / ₂	(114)	7 ³ / ₄	(197)	150	(0.66)
BFP2400-6	6	(150)	6 ⁵ / ₈	(168)	10	(254)	150	(0.66)

BFV751 & BFV751J Beam Clamp

- Design Load Safety Factor of 3
- BFV751J (clip included) must be used when installed on tapered flange beams.
- Material: Glass reinforced polyurethane
- Setscrew material: Stainless Steel 316 ASTM F593 Group 2, S4

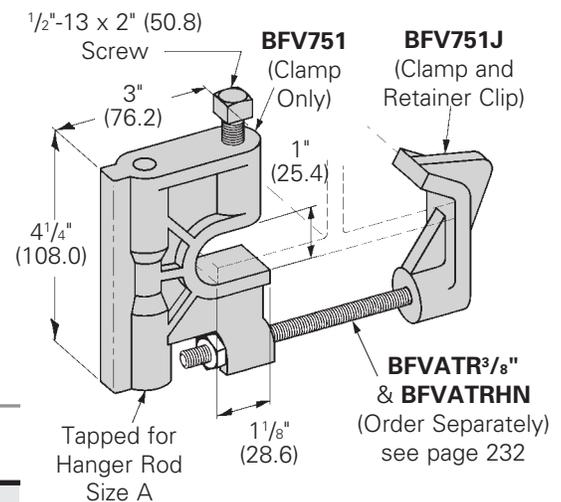

Part No.	For Hanger Rod Size A	Design Load Lbs. kN	Torque ft.-Lbs. N•m
BFV751-3/8	3/8"-16	500 (2.22)	10 (13)
BFV751J-3/8	3/8"-16	500 (2.22)	10 (13)
BFV751-1/2	1/2"-13	500 (2.22)	10 (13)
BFV751J-1/2	1/2"-13	500 (2.22)	10 (13)
BFV751-5/8	5/8"-11	500 (2.22)	10 (13)
BFV751J-5/8	5/8"-11	500 (2.22)	10 (13)

Reference page 224 for general fitting specifications.