

# Conduit & cable



BG\_-S18-W\_



BG\_-S18-W-MC3

| UPC/Part Number | Catalog Number | Conduit Size EMT & Rigid | Box Qty. |
|-----------------|----------------|--------------------------|----------|
|-----------------|----------------|--------------------------|----------|

## W2 Series for #12 thru 1/4" Rod \*\*

|             |                     |              |    |
|-------------|---------------------|--------------|----|
| 78101103578 | <b>BG6-S18-W2 *</b> | 3/8"         | 25 |
| 78101103577 | <b>BG812-S18-W2</b> | 1/2" or 3/4" | 25 |
| 78101103577 | <b>BG16-S18-W2</b>  | 1"           | 25 |

## W2 Series for #12 thru 1/4" Rod & Multiple Conduit Plate \*\*


|             |                         |              |    |
|-------------|-------------------------|--------------|----|
| 78205152855 | <b>BG6-S18-W2-MC3 *</b> | 3/8"         | 25 |
| 78205152739 | <b>BG812-S18-W2-MC3</b> | 1/2" or 3/4" | 25 |
| 78205152862 | <b>BG16-S18-W2-MC3</b>  | 1"           | 25 |

## W6 Series for 3/8" Plain or Threaded Rod \*\*

|             |                     |              |    |
|-------------|---------------------|--------------|----|
| 78110199581 | <b>BG6-S18-W6 *</b> | 3/8"         | 25 |
| 78110199582 | <b>BG812-S18-W6</b> | 1/2" or 3/4" | 25 |
| 78110199580 | <b>BG16-S18-W6</b>  | 1"           | 25 |

## W6 Series for 3/8" Plain or Threaded Rod & Multiple Conduit Plate \*\*

|             |                         |              |    |
|-------------|-------------------------|--------------|----|
| 78205152856 | <b>BG6-S18-W6-MC3 *</b> | 3/8"         | 25 |
| 78205152860 | <b>BG812-S18-W6-MC3</b> | 1/2" or 3/4" | 25 |
| 78205152864 | <b>BG16-S18-W6-MC3</b>  | 1"           | 25 |

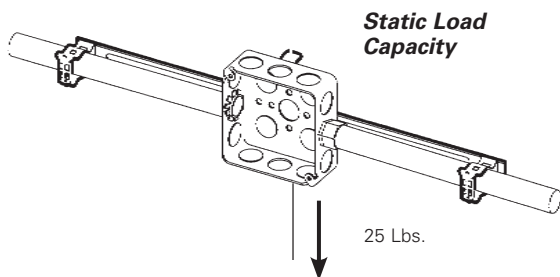

\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ :  
14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit

\*\* Note:

An independent means of support is required by NEC Article 300.11.

Read safety/installation instruction sheets in packages before use.