


## KwikWire Bolt Termination




**Box Quantity - 20**  
5 bags containing 4 pieces per bag

| Part No.             | Thread Size | Wire Rope Dia. |       | Length |        |
|----------------------|-------------|----------------|-------|--------|--------|
|                      |             | in.            | mm    | in.    | mm     |
| <b>BKB25-063-40</b>  | 1/4"-20     | 1/16"          | (1.6) | 40"    | (1016) |
| <b>BKB25-063-80</b>  | 1/4"-20     | 1/16"          | (1.6) | 80"    | (2032) |
| <b>BKB25-063-120</b> | 1/4"-20     | 1/16"          | (1.6) | 120"   | (3048) |
| <b>BKB25-063-180</b> | 1/4"-20     | 1/16"          | (1.6) | 180"   | (4572) |
| <b>BKB25-063-240</b> | 1/4"-20     | 1/16"          | (1.6) | 240"   | (6096) |
| <b>BKB25-063-360</b> | 1/4"-20     | 1/16"          | (1.6) | 360"   | (9144) |
| <b>BKB38-094-40</b>  | 3/8"-16     | 3/32"          | (2.3) | 40"    | (1016) |
| <b>BKB38-094-80</b>  | 3/8"-16     | 3/32"          | (2.3) | 80"    | (2032) |
| <b>BKB38-094-120</b> | 3/8"-16     | 3/32"          | (2.3) | 120"   | (3048) |
| <b>BKB38-094-180</b> | 3/8"-16     | 3/32"          | (2.3) | 180"   | (4572) |
| <b>BKB38-094-240</b> | 3/8"-16     | 3/32"          | (2.3) | 240"   | (6096) |
| <b>BKB38-094-360</b> | 3/8"-16     | 3/32"          | (2.3) | 360"   | (9144) |

- Ideal for use with ARS, ARC, ADI, ACPW, or ACPD anchors.
- Available as a wire rope with bolt termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".
- Available in single, double (Y), and triple leg (3) styles
- All (Y) and triple (3) styles are non-stock, contact us for lead times

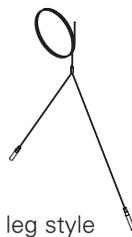

Double (Y) leg style

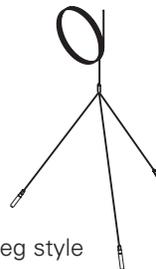

Triple (3) leg style