


- Quickly attaches conduit to beams.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

Push-Type Conduit To Beam Fasteners



UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101119275	BP-8-E-2-4	½" EMT	⅛" - ¼"	100
78101119280	BP-8-E-5-8	½" EMT	⅝" - ½"	100
78101119285	BP-8-E-9-12	½" EMT	⅞" - ¾"	100
78101119375	BP-12-E-2-4	¾" EMT ½" IMC, Rigid	⅛" - ¼"	100
78101119380	BP-12-E-5-8	¾" EMT ½" IMC, Rigid	⅝" - ½"	100
78101119385	BP-12-E-9-12	¾" EMT ½" IMC, Rigid	⅞" - ¾"	100
78101119465	BP-16-E-2-4	1" EMT ¾" IMC, Rigid	⅛" - ¼"	100
78101119470	BP-16-E-5-8	1" EMT ¾" IMC, Rigid	⅝" - ½"	100
78101119475	BP-16-E-9-12	1" EMT ¾" IMC, Rigid	⅞" - ¾"	100

**Ultimate
Static Load
Capacity**

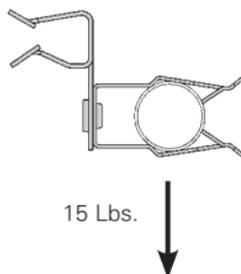

*Read safety/installation instruction sheets in packages before use.
These products are designed for positioning only. No load rating.*