


# Conduit & cable

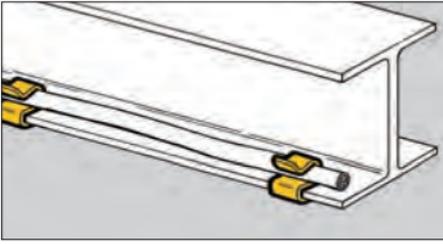

- Secures cable along flanges 1/16" to 3/4"
- The BFA flange adapters attach BXS series to thicker flanges.
- BX\_-67 accepts 14/2, 12/2 & 10/2 romex with ground.
- BX\_-1011 accepts 14/2, 12/2 & 10/2 romex with ground.
- BX\_-1214 accepts 10/3, romex with ground.
- Finish: Zinc Plated.

## Flexible Conduit/ Cable Fasteners



BFA Series  
(For Use with  
BXS Series Only)



BXS  
Series



BXL  
Series

UPC/Part Number	Catalog Number	Flange Thickness	Cable Diameter	Box Qty.
78101119973	<b>BXS-67</b>	1/16" - 5/32"	.218 to .281	100
78101119974	<b>BXS-89</b>	1/16" - 5/32"	.290 to .375	100
78101119975	<b>BXS-1011</b>	1/16" - 5/32"	.375 to .437	100
78101119976	<b>BXS-1214</b>	1/16" - 5/32"	.444 to .560	100
78101119977	<b>BXS-1519</b>	1/16" - 5/32"	.500 to .718	100
78101119978	<b>BXS-2024</b>	1/16" - 5/32"	.748 to .945	100
78101119979	<b>BXS-2530</b>	1/16" - 5/32"	.968 to 1.250	100
78101119980	<b>BXM-67</b>	5/32" - 9/32"	.218 to .281	100
78101119981	<b>BXM-89</b>	5/32" - 9/32"	.290 to .375	100
78101119982	<b>BXM-1011</b>	5/32" - 9/32"	.375 to .437	100
78101119983	<b>BXM-1214</b>	5/32" - 9/32"	.444 to .560	100
78101119984	<b>BXM-1519</b>	5/32" - 9/32"	.500 to .718	100
78101119985	<b>BXM-2024</b>	5/32" - 9/32"	.748 to .945	100
78101119986	<b>BXM-2530</b>	5/32" - 9/32"	.968 to 1.250	100
78101119987	<b>BXL-67</b>	5/16" - 1/2"	.218 to .281	100
78101119988	<b>BXL-89</b>	5/16" - 1/2"	.290 to .375	100
78101119989	<b>BXL-1011</b>	5/16" - 1/2"	.375 to .437	100
78101119990	<b>BXL-1214</b>	5/16" - 1/2"	.444 to .560	100
78101119991	<b>BXL-1519</b>	5/16" - 1/2"	.500 to .718	100
78101119992	<b>BXL-2024</b>	5/16" - 1/2"	.748 to .945	100
78101119993	<b>BXL-2530</b>	5/16" - 1/2"	.968 to 1.250	100
78101119955	<b>BFA-1215</b>	1/2" - 5/8"	—	100
78101119956	<b>BFA-1520</b>	5/8" - 3/4"	—	100

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.