

CenterPoint Energy - Single Meter Sockets (Ringless)

320 Amp



EL32T76GR1E
(open)



EL32T44GRST
(open)

Application

- Single meter position
- Receive ANSI C12.10 watt-hour meters
- Surface mount

Construction

- Ringless cover
- NEMA Type 3R
- ANSI 61 gray E-coat finish



Standards

- UL 414 Listed
- ANSI C12.7

Accessories

- 5th Jaw Kit - 50366
- 200A Triplex Ground - ETB200
- AW Hub, H Hub
- 7th Jaw Kit - 50368

Part/UPC Number	Catalog Number	Amp Rating	Jaws	Service Type	Bypass	Access	Utility [†]	Connections		
								Line	Load	Neutral
78205140883	EL32T44GRST	320	4	1Ø/3W	Lever	UG (Bussed)	CenterPoint	3/8" Studs	3/8" Studs	3/8" Studs
78205138485	EL32T46GRST	320	4	1Ø/3W	Lever	OH/UG (Bussed)	CenterPoint	3/8" Studs	3/8" Studs	3/8" Studs
78205178095	EL32L53GR1E	320	5	1Ø/3W or 3Ø/3W	Lever	OH/UG	CenterPoint	(2) #6 - 250 MCM	(2) #6 - 250 MCM	(2) #6 - 250 MCM
79903860556	EL32T74GR1E	320	7	3Ø/4W	Lever	UG (Bussed)	CenterPoint	3/8" Studs	3/8" Studs	3/8" Studs
78205178094	EL32T76GR1E	320	7	3Ø/4W	Lever	OH/UG (Bussed)	CenterPoint	3/8" Studs	3/8" Studs	3/8" Studs

Part/UPC Number	Catalog Number	Overall Dimensions			Top Provision	Knockout Layout
		Height	Width	Depth		
78205140883	EL32T44GRST	27 ⁵ / ₈ "	18 ¹ / ₄ "	6 ¹ / ₂ "	--	Fig. 1
78205138485	EL32T46GRST	36 ⁵ / ₈ "	18 ¹ / ₄ "	6 ¹ / ₂ "	H Hub, Cap	Fig. 2
78205178095	EL32L53GR1E	36 ¹ / ₈ "	16 ¹ / ₈ "	6 ¹ / ₂ "	H Hub, Cap	Fig. 3
79903860556	EL32T74GR1E	27 ⁵ / ₈ "	20 ¹ / ₄ "	6 ¹ / ₂ "	--	Fig. 1
78205178094	EL32T76GR1E	39 ¹ / ₈ "	20 ¹ / ₄ "	6 ¹ / ₂ "	H Hub, Cap	Fig. 1

[†] Utilities shown are brand names of their respective owners.




CenterPoint Energy - Single Meter Sockets (Ringless)

320 Amp

Knockouts - Conduit Sizes

1Y = $\frac{5}{16}$ "
 2B = $\frac{3}{4}$ " - $\frac{1}{2}$ "
 4J = $3\frac{1}{2}$ " - 3" - $2\frac{1}{2}$ " - 2"
 4K = 4" - $3\frac{1}{2}$ " - 3" - $2\frac{1}{2}$ "
 Top Provision = See Chart

Knockout Layouts

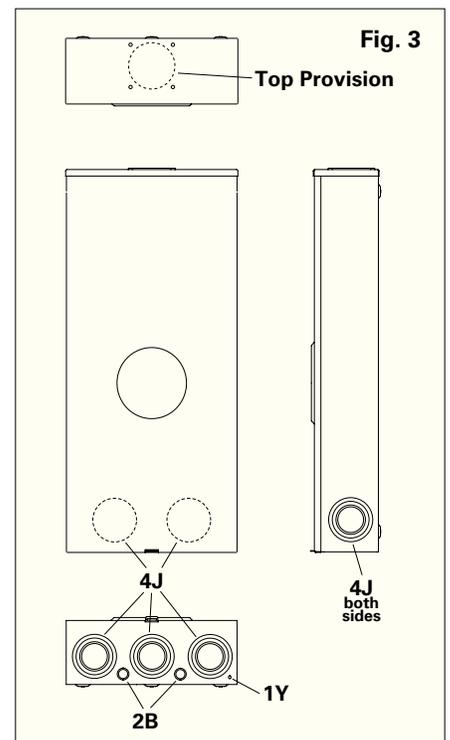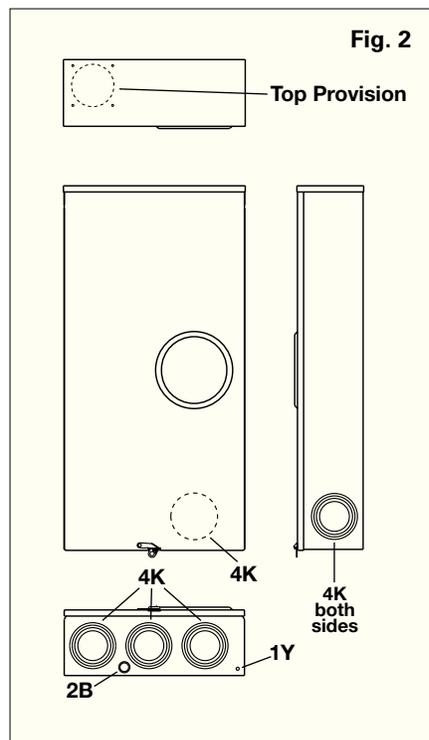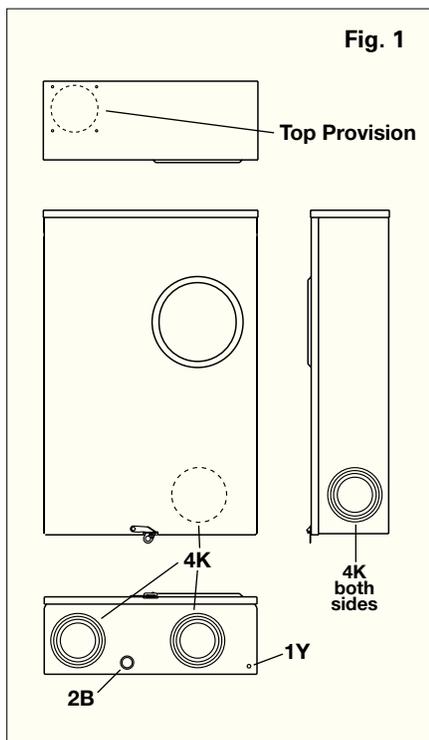

Data subject to change without notice. Consult local utility for area acceptance. All dimensions are in inches.