

Network Equipment Racks & Accessories

Eaton offers two-post, four-post, fixed wall mount, swing gate wall mount, and seismic zone 4 open frame racks and accessories to support networking equipment and cabling for enterprise data centers, colocation providers and network closets.

- Two-post racks - designed to meet a variety of application requirements.
- Two-post seismic racks - for areas where shock and vibration are a factor and is tested to NEBS GR-63-Core Seismic Zone 4 standards and rated for 900 lbs. of equipment.
- Four-post racks - adjustable depth four-post rack offerings address these needs while also accommodating other Eaton equipment and cable management accessories.

Material:	Type	Thickness	Specifications
	Steel Bar	3/8" (9.5mm) - 7 Gauge (4.5mm)	ASTM A36
	Steel Sheet & Strip	10 Gauge (3.4mm) - 18 Gauge (1.2mm)	ASTM A569
	Aluminum		5052-H32, 6061-T6 & 6063-T6

Finishes:

Brushed Aluminum (AL)

Powder Coat Paint

- Flat Black (FB)

- Telco Gray (TG)

- Eaton White (EW)

- Silver (SL)

Chemical Conversion Coatings Available

- Yellow Zinc (YZ) . ASTM B633

- Black Zinc (BZ) . . ASTM B633



(AL)
Brushed
Aluminum



(TG)
Telco Gray



 
(EW)
Eaton White



(FB)
Flat Black
&
(BZ)
Black Zinc



(YZ)
Yellow Zinc



(SL)
Silver

Standard Conformance:

EIA/ECA-310-E

UL Listed Communication Circuit Accessory (file no. E171936)

Audio/Video, Information and Communication Technology Equipment

Cabinet, Enclosure and Rack Systems

Unequal Flange Equipment Racks & Accessories


Unequal Flange

ACCESSORIES Spacer Cover

- Use to create and cover wider cable duct between unequal flange equipment racks
- Includes: (1) cover, bars and hardware
- See SB5615 for spacer box
- Material: ASTM A1011CS steel
- Finish ____: Telco gray powder coat (TG)
Other finishes are available upon request

Part Number	Weight	
	Lbs.	(kg)
2" (51mm) Cover Width		
SB56172084__	5.9	(2.67)
SB56172090__	6.3	(2.86)
SB56172096__	6.7	(3.04)
SB56172108__	7.6	(3.45)
SB56172138__	9.8	(4.44)
SB56172140__	9.9	(4.49)
2½" (63mm) Cover Width		
SB56172½084__	7.3	(3.31)
SB56172½090__	7.8	(3.54)
SB56172½096__	8.3	(3.76)
SB56172½108__	9.7	(4.40)
SB56172½138__	12.2	(5.53)
SB56172½140__	12.4	(5.62)
3" (76mm) Cover Width		
SB56173084__	8.7	(3.94)
SB56173090__	9.4	(4.26)
SB56173096__	10.0	(4.53)
SB56173108__	11.4	(5.17)
SB56173138__	14.5	(6.58)
SB56173140__	14.7	(6.67)
5" (127mm) Cover Width		
SB56175084__	14.4	(6.53)
SB56175090__	15.5	(7.03)
SB56175096__	16.5	(7.48)
SB56175108__	18.9	(8.57)
SB56175138__	24.0	(10.88)
SB56175140__	24.4	(11.07)
7½" (190mm) Cover Width		
SB56177½084__	7.3	(3.31)
SB56177½090__	7.8	(3.54)
SB56177½096__	8.3	(3.76)
SB56177½108__	9.7	(4.40)
SB56177½138__	12.2	(5.53)
SB56177½140__	12.4	(5.62)

Specify part number and finish when ordering.

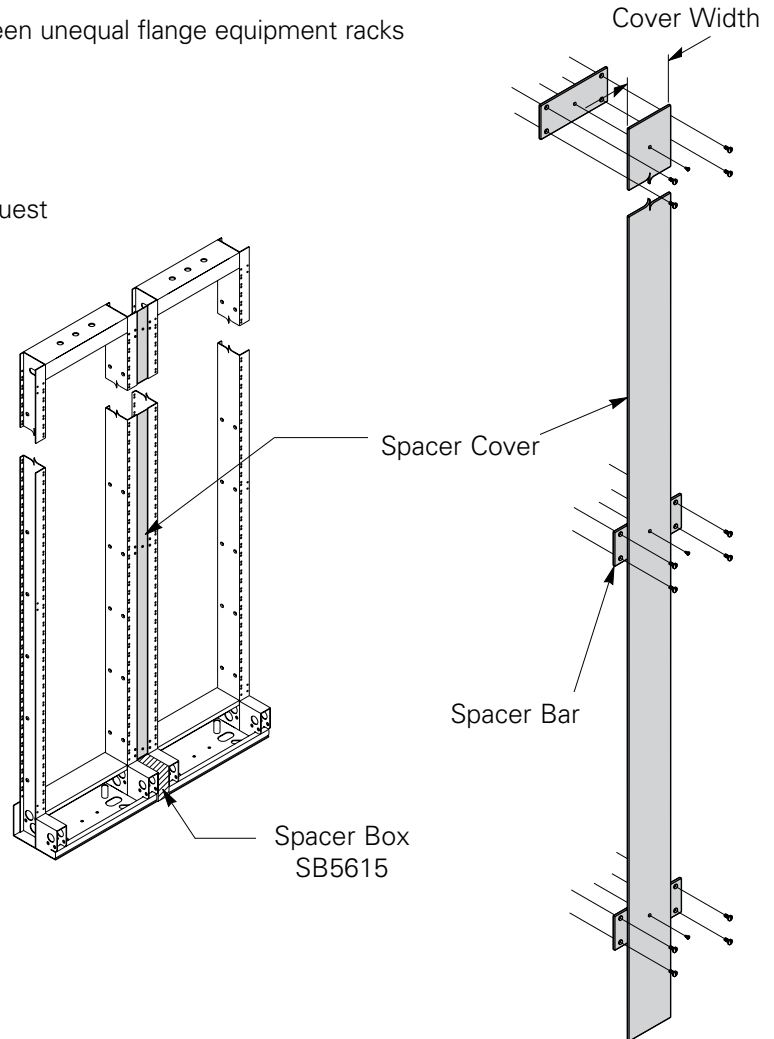

Example Of Part Number

SB5617 2 096

Spacer Cover for
Unequal Flange Equipment Rack
2" (51mm) Width x 96" (2438mm) Height
with 3 Spacer Bars

Code	Rack Height	Spacer Bars Included
084	84" (2134mm)	3
090	90" (2286mm)	3
096	96" (2438mm)	3
108	108" (2743mm)	4
138	138" (3505mm)	4
140	140" (3556mm)	4

Cover Width

2	-	2" (51mm)
2½	-	2½" (63mm)
3	-	3" (76mm)
5	-	5" (127mm)
7½	-	7½" (190mm)