

Network Equipment Racks & Accessories

Eaton offers two-post, four-post, fixed wall mount, swing gate wall mount, and seismic zone 4 open frame racks and accessories to support networking equipment and cabling for enterprise data centers, colocation providers and network closets.

- Two-post racks - designed to meet a variety of application requirements.
- Two-post seismic racks - for areas where shock and vibration are a factor and is tested to NEBS GR-63-Core Seismic Zone 4 standards and rated for 900 lbs. of equipment.
- Four-post racks - adjustable depth four-post rack offerings address these needs while also accommodating other Eaton equipment and cable management accessories.

 
Material:	Type	Thickness	Specifications
	Steel Bar	3/8" (9.5mm) - 7 Gauge (4.5mm)	ASTM A36
	Steel Sheet & Strip	10 Gauge (3.4mm) - 18 Gauge (1.2mm)	ASTM A569
	Aluminum		5052-H32, 6061-T6 & 6063-T6

Finishes:


- Brushed Aluminum (AL)
- Powder Coat Paint
 - Flat Black (FB)
 - Telco Gray (TG)
 - Eaton White (EW)
 - Silver (SL)
- Chemical Conversion Coatings Available
 - Yellow Zinc (YZ) . . . ASTM B633
 - Black Zinc (BZ) . . . ASTM B633



(AL)
Brushed
Aluminum



(TG)
Telco Gray

 


(EW)
Eaton White



(FB)
Flat Black
&
(BZ)
Black Zinc



 (YZ)
Yellow Zinc




(SL)
Silver

Standard Conformance:

- EIA/ECA-310-E
- UL Listed Communication Circuit Accessory (file no. E171936)
- Audio/Video, Information and Communication Technology Equipment Cabinet, Enclosure and Rack Systems

Channel End Guard - Network Bay

- Use to close off wiring duct and protect cabling
- Gives installation a clean professional appearance
- Can be used for either left or right side
- Includes #12-24 x 3/8" (9mm) PHMS (see chart for quantity)
- Material: 11 Ga. (3.0mm) ASTM A1011CS steel
- Finish ____: Telco gray powder coat (TG)
Yellow zinc (YZ)
Other finishes are available upon request

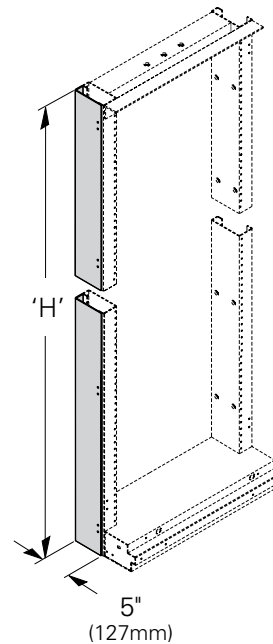

Part Number	'H' Height		Hardware Quantity	Weight	
	in.	(mm)		Lbs.	(kg)
SB5882012 __	11 ⁷ / ₈ "	(301)	4	2.40	(1.1)
SB5882024 __	23 ⁷ / ₈ "	(606)	4	4.90	(2.2)
SB5882054 __	53 ⁷ / ₈ "	(1368)	4	11.00	(5.0)
SB5882056 __	55 ⁷ / ₈ "	(1419)	4	11.40	(5.2)
SB5882084 __	83 ⁷ / ₈ "	(2130)	6	17.12	(7.7)
SB5882090 __	89 ⁷ / ₈ "	(2283)	6	18.32	(8.3)
SB5882096 __	95 ⁷ / ₈ "	(2435)	6	18.32	(8.3)
SB5882108 __	107 ⁷ / ₈ "	(2740)	8	19.52	(8.8)
SB5882138 __	137 ⁷ / ₈ "	(3502)	8	28.12	(12.7)
SB5882140 __	139 ⁷ / ₈ "	(3553)	8	28.52	(12.9)

Specify part number and finish when ordering.