


# Distribution Frames

## Universal Distribution Frame - Single Sided

- Use to support terminal blocks for central office cross connects
- If the vertical terminal blocks are to be corner-mounted, SB658 terminal block mounting plate must be ordered separately
- End guards and grounding strap must be ordered separately
- Includes: frame, universal connector mounting bar, jumper rings, ground bar, guard rail, guard rail support, and hardware
- Material: ASTM A36 structural steel
- Finish \_\_\_\_: Telco gray powder coat (TG)  
Other finishes are available upon request

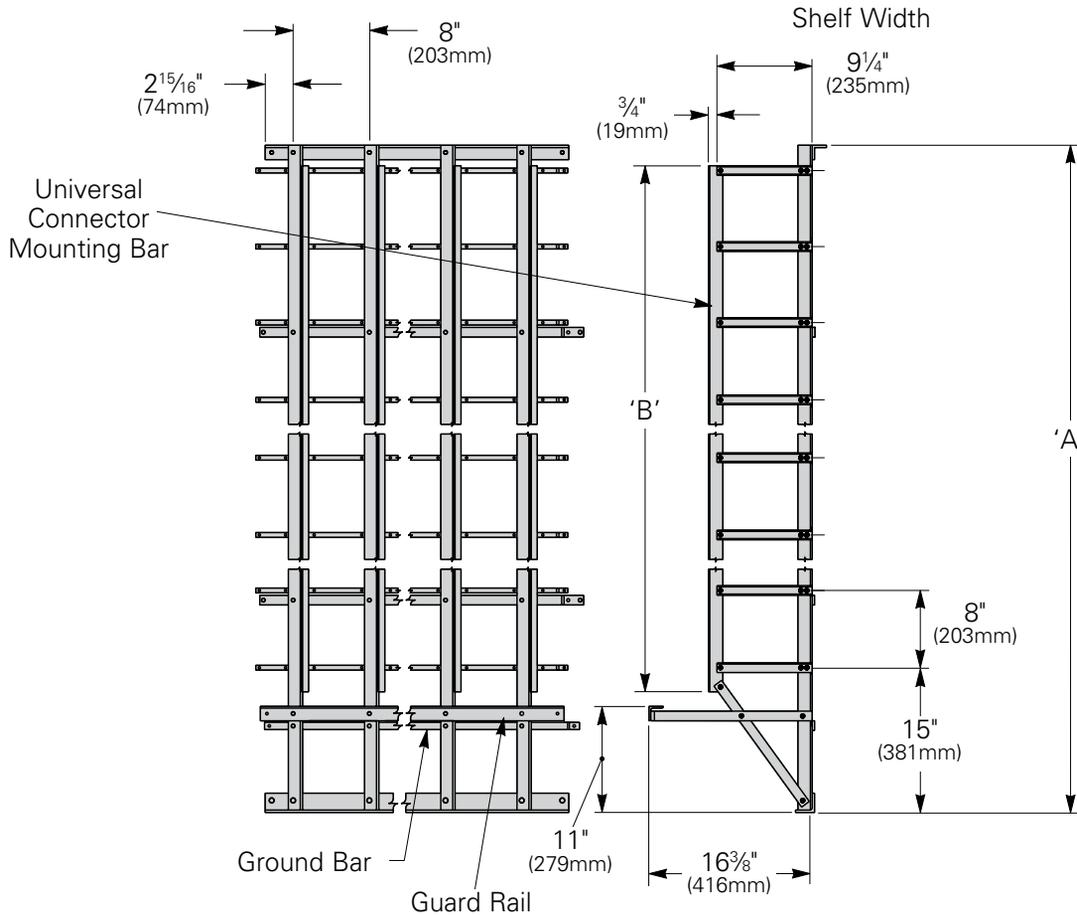

### Part Number Legend

SB-609	Frame Height No. of Shelves	Number of Verticals (*)
Frame Type -	084 (8 shelves)	01 - 1 Vertical
Shelf Width	096 (10 shelves)	02 - 2 Verticals
609 - 9 1/4" (235mm)	108 (12 shelves)	03 - 3 Verticals
	120 (13 shelves)	04 - 4 Verticals
	138 (16 shelves)	05 - 5 Verticals
	140 (16 shelves)	06 - 6 Verticals
		07 - 7 Verticals
		08 - 8 Verticals
	09 - 9 Verticals	
	10 - 10 Verticals	
	11 (No Verticals, End Guards Only)	11 (No Verticals, End Guards Only)
		[End guards for both sides included]
		12 (No Verticals, Junction Kit Only)

### Example: SB60909608

SB609 - [9 1/4" (235mm)]  
096 - [96" (2438mm) tall with 10 shelves]  
08 - [8 Verticals]

## Universal Distribution Frame - Single Sided *continued*

- Finish \_\_\_: Telco gray powder coat (TG)  
Other finishes are available upon request

### Single Sided Frames

Part Number	Frame Height 'A'		'B' Dimension		No. of Shelves
	In.	(mm)	In.	(mm)	
9¼" (235mm) Shelf Width					
<b>SB609084(*)</b> __	84"	(2133)	64"	(1625)	8
<b>SB609096(*)</b> __	96"	(2438)	80"	(2032)	10
<b>SB609108(*)</b> __	108"	(2743)	94"	(2387)	12
<b>SB609120(*)</b> __	120"	(3048)	100"	(2540)	13
<b>SB609138(*)</b> __	138"	(3505)	123"	(3124)	16
<b>SB609140(*)</b> __	140"	(3556)	123"	(3124)	16

Specify part number and finish when ordering.

\* See Part Number Legend on page 350.

### Universal Connector Mounting Bar Capacity

Frame Size (No. of Shelves)	'B'		No. Terminal Blocks	C-303	R-700	C-310 R-710	C-377 R-355 C-388
	In.	(mm)					
Connector Capacity No. of Pairs of Protection							
8	64"	(1625)	7	300	300	400	600
10	80"	(2032)	9	400	400	500	700
12	94"	(2387)	11	500	400	600	800
13	100"	(2540)	12	500	500	700	900
16	123"	(3124)	15	600	600	800	1100