


Heavy Duty Wall Mount Relay Rack

The Heavy Duty Wall Mount Relay Rack provides a economical solution for loads up to 200 lb. static load capacity. This rack is used when equipment and patch panel installations do not require security.


Features

- Extra deep fixed wall rack provides mounting depth up to 30" (762mm)
- Rated for 200 lb. (91kg) load capacity (dependent on wall strength and anchors)
- Double sided universal ($\frac{5}{8}$ " (16mm), $\frac{5}{8}$ " (16mm), $\frac{1}{2}$ " (13mm)) mounting hole spacing
- #12-24 panel mounting holes
- Conformance to EIA-310-D
- 19" (482mm) & 23" (584mm) widths
- 14U = 25" (635mm), 22U = 39" (990mm) and 42U = 72" (1829mm) heights
- 18" (457mm), 24" (609mm) and 30" (762mm) depths
- Material: 6061-T6 aluminum alloy
- Finish: Brushed Aluminum (BRSH)
Telco Gray Powder Coat (TG)
Flat Black Powder Coat (FB) or
Computer White Powder Coat (CW)

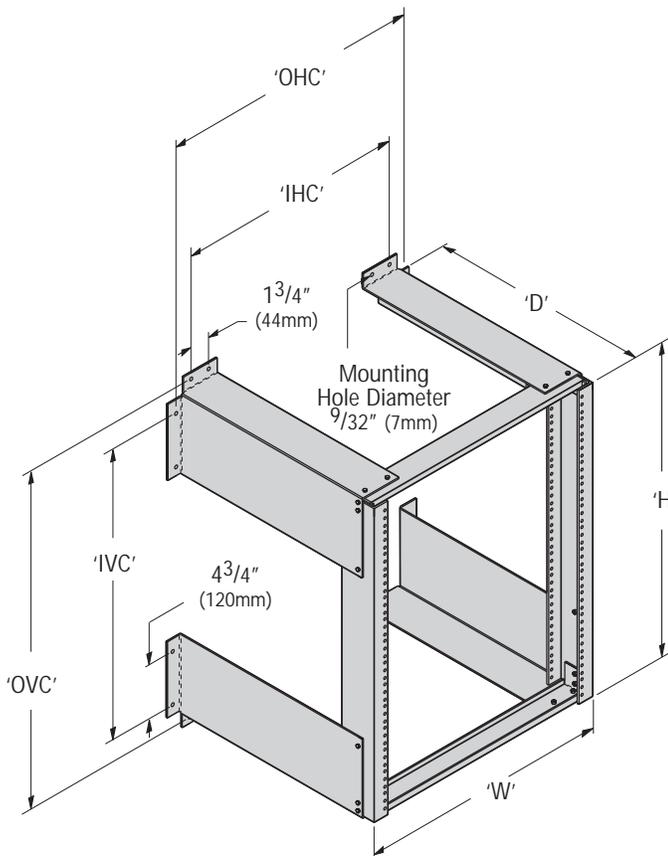

Mtg. U's	Mounting Hole Spacing							
	Horizontal Centers				Vertical Centers			
	Outside 'OHC'		Inside 'IHC'		Outside 'OVC'		Inside 'IVC'	
	in.	(mm)	in.	(mm)	in.	(mm)	in.	(mm)
For 20⁵/₁₆" (516mm) Rack Width								
14	21 ⁹ / ₁₆	548	19 ³ / ₁₆	487	27 ¹ / ₁₆	687	23 ¹¹ / ₁₆	601
22	21 ⁹ / ₁₆	548	19 ³ / ₁₆	487	41 ¹ / ₁₆	1043	37 ¹¹ / ₁₆	957
42	21 ⁹ / ₁₆	548	19 ³ / ₁₆	487	76 ¹ / ₁₆	1932	72 ¹¹ / ₁₆	1846
For 24⁵/₁₆" (617mm) Rack Width								
14	25 ⁹ / ₁₆	649	23 ³ / ₁₆	598	27 ¹ / ₁₆	687	23 ¹¹ / ₁₆	601
22	25 ⁹ / ₁₆	649	23 ³ / ₁₆	598	41 ¹ / ₁₆	1043	37 ¹¹ / ₁₆	957
42	25 ⁹ / ₁₆	649	23 ³ / ₁₆	598	76 ¹ / ₁₆	1932	72 ¹¹ / ₁₆	1846

Heavy Duty Wall Mount Relay Rack

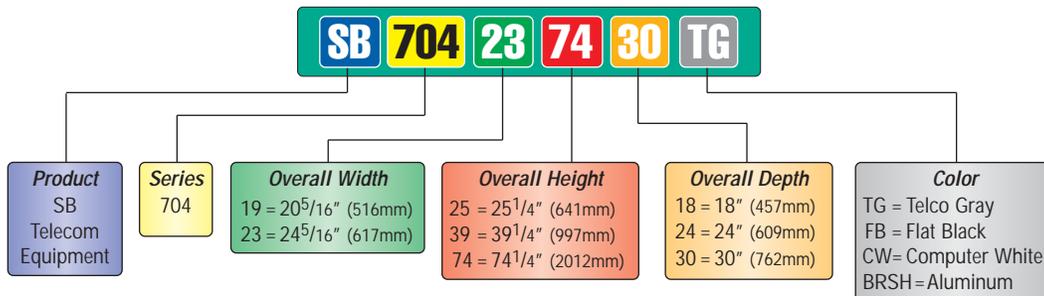

Part Number*	'W' Rack Width		'H' Height		Usable EIA Mounting U's	'D' Depth		Weight	
	in.	(mm)	in.	(mm)		in.	(mm)	lbs.	(kg)
SB704192518	20 ⁵ / ₁₆ "	516	25 ¹ / ₄ "	641	14	18"	457	10.2	4.6
SB704192524	20 ⁵ / ₁₆ "	516	25 ¹ / ₄ "	641	14	24"	609	11.5	5.2
SB704192530	20 ⁵ / ₁₆ "	516	25 ¹ / ₄ "	641	14	30"	762	13.1	5.9
SB704193918	20 ⁵ / ₁₆ "	516	39 ¹ / ₄ "	977	22	18"	457	13.5	6.1
SB704193924	20 ⁵ / ₁₆ "	516	39 ¹ / ₄ "	977	22	24"	609	14.9	6.7
SB704193930	20 ⁵ / ₁₆ "	516	39 ¹ / ₄ "	977	22	30"	762	16.2	7.3
SB704197418	20 ⁵ / ₁₆ "	516	74 ¹ / ₄ "	2012	42	18"	457	21.6	9.8
SB704197424	20 ⁵ / ₁₆ "	516	74 ¹ / ₄ "	2012	42	24"	609	22.9	10.4
SB704197430	20 ⁵ / ₁₆ "	516	74 ¹ / ₄ "	2012	42	30"	762	24.5	11.1
SB704232518	24 ⁵ / ₁₆ "	617	25 ¹ / ₄ "	641	14	18"	457	12.7	5.7
SB704232524	24 ⁵ / ₁₆ "	617	25 ¹ / ₄ "	641	14	24"	609	14.0	6.3
SB704232530	24 ⁵ / ₁₆ "	617	25 ¹ / ₄ "	641	14	30"	762	15.6	7.1
SB704233918	24 ⁵ / ₁₆ "	617	39 ¹ / ₄ "	997	22	18"	457	16.0	7.2
SB704233924	24 ⁵ / ₁₆ "	617	39 ¹ / ₄ "	997	22	24"	609	17.4	7.9
SB704233930	24 ⁵ / ₁₆ "	617	39 ¹ / ₄ "	997	22	30"	762	18.7	8.5
SB704237418	24 ⁵ / ₁₆ "	617	74 ¹ / ₄ "	2012	42	18"	457	24.1	10.9
SB704237424	24 ⁵ / ₁₆ "	617	74 ¹ / ₄ "	2012	42	24"	609	25.4	11.5
SB704237430	24 ⁵ / ₁₆ "	617	74 ¹ / ₄ "	2012	42	30"	762	27.0	12.2

* Add Color Code suffix to complete part number.