

Cable Managers


RCM+ System

RCM+ Rack Mounted Vertical Cable Manager With Cover Double Sided Dual Density Style


- Double-sided SB864 Series cable managers utilize the SB860 and SB862 Series cable managers in back-to-back combination for use in applications with varying cable management requirements
- High-density extended fingers provide maximum cable support for each rack mounting space
- Low-density vertical cabling section can be used with RCM+ horizontal cable managers
- Front and rear vertical sections can be spaced apart when mounting on racks deeper than 3" (76mm), allowing cables to be routed out through side openings created between the vertical sections
- High-density vertical cable section can be used with RCM+ extended horizontal cable manager
- Snap-on gates on both sides allows for quick opening from either side or complete removal
- Open back design allows unrestricted routing of cables between front and rear sections
- Optional back removable covers are designed with pass through openings for cable routing, keyhole slots for cable spools, slots for cable straps, and keyhole slots for direct PDU mounting
- Installation is easy and can be done in minutes using standard hand tools
- 1/4" (6.3mm) accessory mounting holes run the full height on both sides of cable manager to accommodate the attachment of cable management accessories
- UL Listed as a communication circuit accessory. File No. E171936
- Material: Aluminum with UL 94V-0 black plastic components
- Vertical cable manager includes:
 - (2) vertical cabling sections,
 - (1) door, (50) push-in fasteners,
 - (12) cable strap mounts,
 - (4) cable retainer bars, required number of gates and mounting hardware
- Finish___: Flat black powder coat (FB)
Silver powder coat (SL)
Eaton white powder coat (EW)



Top View

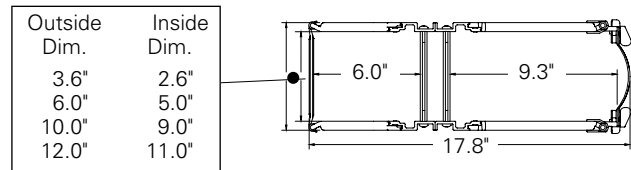

U.S. Patent 7,362,941
Other Patents Pending

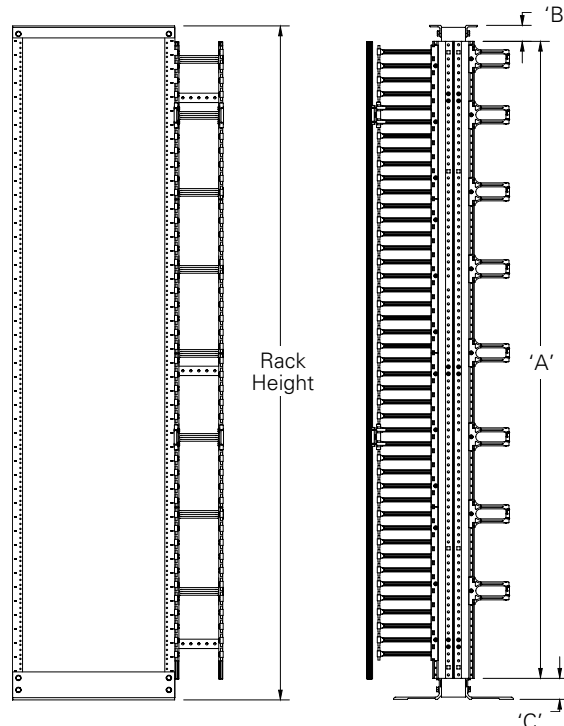

Double sided,
84" high x 6" wide
SB86486D084FB

Cable managers

RCM+ Rack Mounted Vertical Cable Manager cont. Double Sided Dual Density Plastic Gate Style

- Finish___: Flat black powder coat (FB)
Silver powder coat (SL)
Eaton white powder coat (EW)

Part Number	Fits Rack Height of In. (mm)	'A' In. (mm)	'B' In. (mm)	'C' In. (mm)	Weight Each Lbs. (kg)	Max CAT6A Cables (0.375" OD) (50% Fill)
3 ⁵ / ₈ " (92mm) Wide x 17 ⁷ / ₈ " (454mm) Deep						
SB86483D066__	66" (1676)	60 ³ / ₈ " (1533)	3" (76.2)	2 ⁵ / ₈ " (66.7)	19.9 (9.0)	179
SB86483D072__	72" (1829)	67 ³ / ₈ " (1711)	2" (50.8)	2 ⁵ / ₈ " (66.7)	22.3 (10.1)	179
SB86483D078__	78" (1981)	72 ⁵ / ₈ " (1845)	2 ³ / ₄ " (69.9)	2 ⁵ / ₈ " (66.7)	24.1 (10.9)	179
SB86483D084__	84" (2133)	79 ⁵ / ₈ " (2022)	1 ³ / ₄ " (44.4)	2 ⁵ / ₈ " (66.7)	26.0 (11.8)	179
SB86483D090__	90" (2286)	84 ⁷ / ₈ " (2156)	2 ¹ / ₂ " (63.5)	2 ⁵ / ₈ " (66.7)	27.6 (12.5)	179
SB86483D096__	96" (2438)	90 ¹ / ₈ " (2289)	3 ¹ / ₄ " (82.6)	2 ⁵ / ₈ " (66.7)	29.3 (13.3)	179
SB86483D108__	108" (2743)	102 ³ / ₈ " (2600)	3" (76.2)	2 ⁵ / ₈ " (66.7)	33.2 (15.0)	179
6" (152mm) Wide x 17 ⁷ / ₈ " (454mm) Deep						
SB86486D066__	66" (1676)	60 ³ / ₈ " (1533)	3" (76.2)	2 ⁵ / ₈ " (66.7)	21.7 (9.8)	344
SB86486D072__	72" (1829)	67 ³ / ₈ " (1711)	2" (50.8)	2 ⁵ / ₈ " (66.7)	24.3 (11.0)	344
SB86486D078__	78" (1981)	72 ⁵ / ₈ " (1845)	2 ³ / ₄ " (69.9)	2 ⁵ / ₈ " (66.7)	26.3 (11.9)	344
SB86486D084__	84" (2133)	79 ⁵ / ₈ " (2022)	1 ³ / ₄ " (44.4)	2 ⁵ / ₈ " (66.7)	28.4 (12.9)	344
SB86486D090__	90" (2286)	84 ⁷ / ₈ " (2156)	2 ¹ / ₂ " (63.5)	2 ⁵ / ₈ " (66.7)	30.1 (13.6)	344
SB86486D096__	96" (2438)	90 ¹ / ₈ " (2289)	3 ¹ / ₄ " (82.6)	2 ⁵ / ₈ " (66.7)	32.1 (14.5)	344
SB86486D108__	108" (2743)	102 ³ / ₈ " (2600)	3" (76.2)	2 ⁵ / ₈ " (66.7)	36.2 (16.4)	344
10" (254mm) Wide x 17 ⁷ / ₈ " (454mm) Deep						
SB864810D066__	66" (1676)	60 ³ / ₈ " (1533)	3" (76.2)	2 ⁵ / ₈ " (66.7)	25.2 (11.4)	620
SB864810D072__	72" (1829)	67 ³ / ₈ " (1711)	2" (50.8)	2 ⁵ / ₈ " (66.7)	28.3 (12.8)	620
SB864810D078__	78" (1981)	72 ⁵ / ₈ " (1845)	2 ³ / ₄ " (69.9)	2 ⁵ / ₈ " (66.7)	30.4 (13.8)	620
SB864810D084__	84" (2133)	79 ⁵ / ₈ " (2022)	1 ³ / ₄ " (44.4)	2 ⁵ / ₈ " (66.7)	32.9 (14.9)	620
SB864810D090__	90" (2286)	84 ⁷ / ₈ " (2156)	2 ¹ / ₂ " (63.5)	2 ⁵ / ₈ " (66.7)	34.8 (15.8)	620
SB864810D096__	96" (2438)	90 ¹ / ₈ " (2289)	3 ¹ / ₄ " (82.6)	2 ⁵ / ₈ " (66.7)	37.2 (16.9)	620
SB864810D108__	108" (2743)	102 ³ / ₈ " (2600)	3" (76.2)	2 ⁵ / ₈ " (66.7)	42.0 (19.0)	620
12" (305mm) Wide x 17 ⁷ / ₈ " (454mm) Deep						
SB864812D066__	66" (1676)	60 ³ / ₈ " (1533)	3" (76.2)	2 ⁵ / ₈ " (66.7)	29.4 (13.3)	757
SB864812D072__	72" (1829)	67 ³ / ₈ " (1711)	2" (50.8)	2 ⁵ / ₈ " (66.7)	32.9 (14.9)	757
SB864812D078__	78" (1981)	72 ⁵ / ₈ " (1845)	2 ³ / ₄ " (69.9)	2 ⁵ / ₈ " (66.7)	35.5 (16.1)	757
SB864812D084__	84" (2133)	79 ⁵ / ₈ " (2022)	1 ³ / ₄ " (44.4)	2 ⁵ / ₈ " (66.7)	38.3 (17.4)	757
SB864812D090__	90" (2286)	84 ⁷ / ₈ " (2156)	2 ¹ / ₂ " (63.5)	2 ⁵ / ₈ " (66.7)	40.6 (18.4)	757
SB864812D096__	96" (2438)	90 ¹ / ₈ " (2289)	3 ¹ / ₄ " (82.6)	2 ⁵ / ₈ " (66.7)	48.5 (19.7)	757
SB864812D108__	108" (2743)	102 ³ / ₈ " (2600)	3" (76.2)	2 ⁵ / ₈ " (66.7)	48.9 (22.2)	757

Specify part number and finish when ordering.

A = Height of RCM+ vertical section without doors

B = Distance between the top of the rack and the top of the RCM+ cable manager

C = Distance between the floor and the lowest part of the RCM+ cable manager

Note: Doors are not furnished on rear side cable managers.