




## Cleanroom Swabs

### Coventry™ High Precision ESD Static Control Swabs

*Protects components from destructive static discharge*

Engineered to eliminate damage from static electricity. The handles of these swabs will dissipate 99% of a 5,000 volt (5 KV) charge in less than 2.0 seconds. The static dissipative plastic alloy used to make the handles is inherently static dissipative. It contains no additives, coatings or surfactants so it functions at any level of humidity and it is very resistant to solvents — even acetone. Choose between our Class 10 (M3, ISO 4) laundered polyester or 100 pore-per-inch ultraclean polyurethane foam.

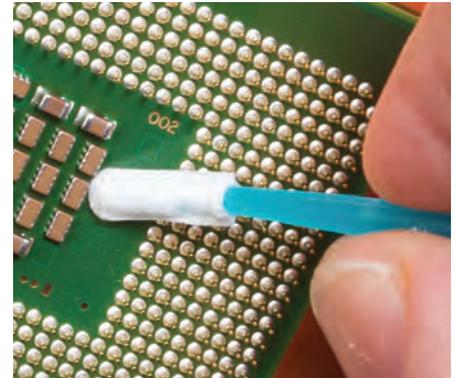

### Coventry™ Sealed Polyester ESD Swabs

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Width	Handle Material	Head Material
36060ESD	500 swabs	5.8" 14.7 cm	0.12" 3.1 mm	0.75" 18.9 mm	0.19" x 0.21" 4.7 mm x 5.4 mm	ESD	knit polyester
31040ESD	500 swabs	2.8" 7.2 cm	0.10" 2.7 mm	0.44" 11.0 mm	0.12" x 0.12" 3.1 mm x 3.1 mm	ESD	knit polyester
38540ESD	500 swabs	2.7" 6.9 cm	0.09" 2.2 mm	0.47" 12.0 mm	0.16" x 0.16" 4.0 mm x 4.0 mm	ESD	non-woven polyester
36861CLR	500 swabs	6.5" 16.5 cm	0.12" 3.0 mm	0.67" 17.0 mm	0.28" x 0.14" 7.0 mm x 3.5 mm	ESD	knit polyester

### Coventry™ Polyester Pillow-Tip™ ESD Swabs

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Width	Handle Material	Head Material
51121ESD	25 swabs	2.8" 7.1 cm	0.10" 2.5 mm	0.40" 10.2 mm	0.25" x 0.23" 6.5 mm x 5.7 mm	ESD	knit polyester