

# SS SERIES

## STAINLESS STEEL SPRING RETRACTABLE HOSE REELS

**COXREELS® SS Series** "Stainless Steel" spring driven hose reels have similar features to their related series, but are constructed of high quality electro-polished stainless steel with stainless steel fluid paths. They offer clean, non-corrosive performance in applications that require it, such as food and chemical processing, marinas, and anywhere that rust, corrosion and contamination thrive.

### P SERIES - Spring Rewind

LESS HOSE						SIZE INDEX
MODEL	I.D.	O.D.	FT.	PSI	APRX. LBS.	
<b>P-LPL-335-SS</b>	3/8"	21/32"	35	300	34	<b>1</b>
<b>P-LPL-350-SS</b>	3/8"	21/32"	50	300	39	<b>1</b>
<b>P-LPL-425-SS</b>	1/2"	21/32"	25	300	39	<b>2</b>

### SH, & MP SERIES - Spring Rewind

LESS HOSE						SIZE INDEX
MODEL	I.D.	O.D.	FT.	PSI	APRX. LBS.	
<b>SHL-N-350-SS</b>	3/8"	21/32"	50	300	44	<b>3</b>
<b>SHL-N-450-SS</b>	1/2"	27/32"	50	300	46	<b>3</b>
<b>SHL-N-525-SS</b>	3/4"	15/32"	25	300	45	<b>4</b>
<b>MPL-N-350-SS</b>	3/8"	5/8"	50	3000	53	<b>3</b>
<b>MPL-N-450-SS</b>	1/2"	3/4"	50	2500	53	<b>3</b>

### T SERIES - Spring Rewind

LESS HOSE						SIZE INDEX
MODEL	I.D.	O.D.	FT.	PSI	APRX. LBS.	
<b>TSHL-N-4100-SS</b>	1/2"	27/32"	100	300	80	<b>5</b>
<b>TSHL-N-550-SS</b>	3/4"	15/32"	50	300	70	<b>6</b>

### EN SERIES - Spring Rewind


LESS HOSE						SIZE INDEX
MODEL	I.D.	O.D.	FT.	PSI	APRX. LBS.	
<b>ENL-N-335-SS</b>	3/8"	21/32"	35	300	46	<b>7</b>
<b>ENL-N-350-SS</b>	3/8"	21/32"	50	300	58	<b>8</b>
<b>ENL-N-450-SS</b>	1/2"	27/32"	50	300	61	<b>8</b>

### REEL DIMENSIONS

Technical Data Sheets Available On Website

SIZE INDEX	W	H	L	X	Y	M	N
<b>1</b>	6 3/4"	18 5/8"	17 1/8"	6"	6"	4"	5"
<b>2</b>	7"	18 5/8"	17 1/8"	6"	6"	4"	5"
<b>3</b>	8 1/4"	21 1/4"	19 1/2"	6"	6"	4"	5"
<b>4</b>	9 3/8"	21 1/4"	19 1/2"	6"	6"	4"	5"
<b>5</b>	9 3/8"	25 1/2"	24"	8"	9"	7"	8"
<b>6</b>	9 7/8"	25 1/2"	24"	8"	9"	7"	8"
<b>7</b>	6 7/8"	18 7/8"	19"	6"	6"	4"	5"
<b>8</b>	8 1/2"	21 3/4"	21 7/8"	6"	6"	4"	5"

Overall Dimensions      Base      Mounting Pattern

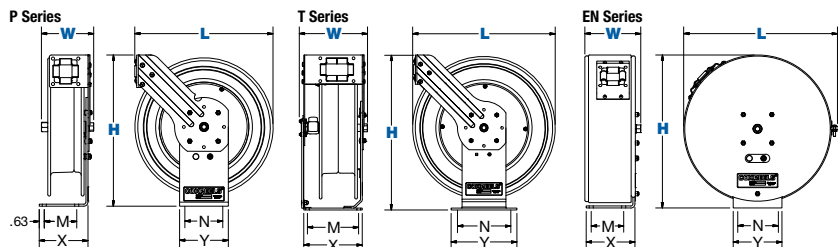

### SS SERIES - SPRING - REEL SPECIFICATIONS

#### SWIVEL

- Non-corrosive external fluid path with machined from high quality stainless steel 90° full-flow NPT swivel inlet
- Swivel Seals: NITRILE Non-Toxic Food Grade Grease

#### DESIGN & STRUCTURE

- Electro-polished stainless steel finish
- Each of these reels is built of their standard series with their own unique features & benefits

#### RETRACTION

- See page 11 For P Series spring driven features
- See page 12 For SH & MP Series spring driven features
- See page 13 For T Series spring driven features
- See page 16 For EN Series spring driven features

#### SIGNATURE FEATURES

- Professional grade heavy duty steel construction
- Durable proprietary CPC™ powder coat process
- Rolled edges & ribbed discs provide strength & safety
- Leading 2-year manufacturer's limited warranty
- Made in the U.S.A. - Sold & Supported Worldwide

#### POSSIBLE FIELDS OF APPLICATION

- Corrosive Environments
- Hygienic Environments
- Medical Services
- Marine/Docks/Offshore
- Manufacturing Plants & Facilities
- Pulp & Paper Plants
- Food & Chemical Processing Plants
- Bottling Plants
- Dairies
- Meat Packing
- Grocery Stores
- Restaurants & Commercial Kitchens
- Water Treatment & Supply
- Petrochemical
- Food Grade Washdown

#### ACCESSORIZE YOUR REEL :: PG 50

- O-Rings & Swivels
- Mounting Brackets
- Hoses
- Assorted Reel Accessories

