

CST/berger.

Robotics Tripods

Aluminum

Cat.#	Type	Extended	Closed	Net Wt	Fastener
60-RT20ALW	Aluminum	63" (160cm)	38" (97cm)	-	5/8-11
60-RT20WDF	Composite	71"	46" (117cm)	-	5/8-11
60-RT20FG	Composite/Wood	71"	46" (117cm)	-	5/8-11

GPS Receiver Tripod

Mast Height: 84" (213cm). Total Extension Height Open: 10'-5" (317cm)

Cat.#	Extended	Closed	Net Wt	Fastener
60-WDF20MST	72" (183cm)	42" (107cm)	17lb (7.8kg)	5/8-11

Machine Control Tripods

Elevator column allows a height adjustment range of 17" (43cm)

Cat.#	Extended	Closed	Net Wt	Fastener
60-MCT	135" (343cm)	72" (183cm)	29lb (13kg)	5/8-11
60-MCTE	171" (434cm)	84" (213cm)	34lb (15.4kg)	5/8-11

NOTE: All MCT Tripods include Heavy Duty Points as well as industrial grade casters for interior applications.



60-RT20ALW Tripod



60-MCTE Tripod

TRIPOD ACCESSORIES

Cat.#	Description
60-TFG20	Tripod Floor Guide
60-BAG20	Tripod Carrying Bag fits tripods up to 45" (114cm) in closed length.
61-2512	Universal Plastic Tripod Cap, 5/8-11 thread



60-TFG20 Floor Guide

CST/berger.

Tripod Adapters

Easily adapt a tripod to fit your instrument.

Cat.#	Tripod Fastener	Adapts to Instrument Size
61-2506	5/8-11	11/16 X 20
61-2507	1/2-20	11/16 X 20
61-2508	1/2-20	5/8 X 11
61-2509	5/8-11	1/2-20
61-2510	5/8-11	3 1/2-8
61-2510A	3 1/2-8	5/8-11
61-2516	1/4-20	1/4-20
61-2517	5/8-11	1/4-20




CST/berger.

RODS

Telescoping Rods

Cat.#	Length	UOM	Type	Section
06-805MC	16-ft/5m	Metric Ft/In/8ths	Aluminum	5
06-805MT	16-ft/5m	Metric Ft/In/100ths	Aluminum	5
06-808A	8-ft	Feet/10ths/100ths	Aluminum	3
06-808C	8-ft	Feet/Inches/8ths	Aluminum	3
06-808M	2.5m	Metric	Aluminum	3
06-913	13-ft	Feet/10ths/100ths	Fiberglass	4
06-913C	13-ft	Feet/Inches/8ths	Fiberglass	4
06-813	13-ft	Feet/10ths/100ths	Aluminum	4
06-813C	13-ft	Feet/Inches/8ths	Aluminum	4
06-904M	4m	Metric	Fiberglass	4
06-9042MM	4m	Dm/Cm/2mm	Fiberglass	4
06-804M	4m	Metric/mm	Aluminum	4
06-8042MM	4m	Dm/Cm/2mm	Aluminum	4
06-916	16-ft	Feet/10ths/100ths	Fiberglass	5
06-916C	16-ft	Feet/Inches/8ths	Fiberglass	5

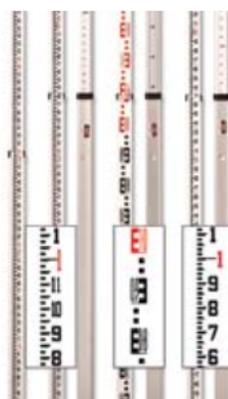

Bayonet Rod

Quik-Lok Pole

Cat.#	Length	UOM	Type	Section
06-716	16-ft	Feet/10ths/100ths	Fiberglass	4
06-716C	16-ft	Feet/Inches/8ths	Fiberglass	4
06-816	16-ft	Feet/10ths/100ths	Aluminum	5
06-816C	16-ft	Feet/Inches/8ths	Aluminum	5
06-905M	5m	Metric	Fiberglass	5
06-905MMM	5m	1/2 cm/mm	Fiberglass	5
06-705M	5m	Metric	Fiberglass	4
06-805M	5m	Metric	Aluminum	5
06-805MMM	5m	1/2 cm/mm	Aluminum	5
06-925	25-ft	Feet/10ths/100ths	Fiberglass	6
06-925C	25-ft	Feet/Inches/8ths	Fiberglass	6
06-725	25-ft	Feet/10ths/100ths	Fiberglass	6
06-725C	25-ft	Feet/Inches/8ths	Fiberglass	6
06-907M	7.6m	Metric	Fiberglass	6
06-707M	7.6m	Metric	Fiberglass	6

CST/berger.

Laser Rods and Poles

Bayonet and Quik-Lok

Cat.#	Length	Unit of Measure	Type	Section
09-2082E	8-ft	Feet/Inches/8ths	2	3
09-2082T	8-ft	Feet/Inches/100ths	Bayonet	2
09-2082M	2.5m	Metric	Bayonet	2
09-4154T	15-ft	Feet/Inches/100ths	Quik-Lok	4
09-4154E	15-ft	Feet/Inches/100ths	Quik-Lok	4
06-4154M	4.6m	Metric	Quik-Lok	4

"Cut and Fill" Rod

Cat.#	Length	UOM	Section	Extras
06-TLM	2.4m	Metric	2	
06-TLC	8-ft	Feet/Inches/8ths	2	
06-TLMB	2.4m	Metric	2	Bubble Vial
06-TLCB	8-ft	Feet/Inches/100ths	2	Bubble Vial

"Cut and Fill" Rod