

## KFP 20 S AL 12 (706 300)



Figure without obligation

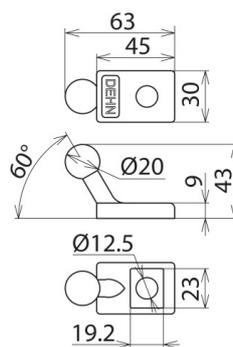


Figure without obligation

Type	KFP 20 S AL 12
Part No.	706 300
Fixed ball point Ø	20 mm
Bore Ø	12.5 mm
Dimensions	45 x 30 x 9 mm
Max. cable cross-section Cu	50 mm <sup>2</sup>
Max. short-circuit current I <sub>k</sub> 0.5 s	14.0 kA
Max. short-circuit current I <sub>k</sub> 1 s	9.9 kA
Standard	EN/IEC 61230 (DIN VDE 0683-100) and based on DIN 48088-1
Material (fixed ball point)	E-Cu/gal Sn
Weight	129 g
Customs tariff number (Comb. Nomenclature EU)	85359000
GTIN	4013364003675
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.