

### BEV OL NPF K (750 210)

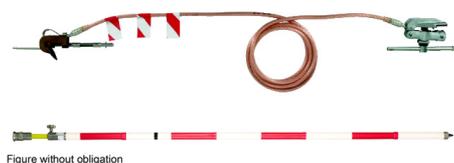


Figure without obligation

Kit includes:		
Type	Part No.	Pos. No.
Tommy bar (K) or ratchet (R)		
EKV K 50 8500	1x 751 086	<b>1+4+7</b>
ESTC SQL RW 5000	1x 769 502	<b>12</b>

Figure without obligation

Type	BEV OL NPF K
Part No.	750 210
Design	Tommy bar
Type of cable	Single-pole
Cable cross-section (phase side)	50 mm <sup>2</sup>
Cable cross-section (earth side)	50 mm <sup>2</sup>
Length (single-pole cable)	8500 mm
Fully insulated	No
Cable length	8500 mm
Standard	EN/IEC 61230 (DIN VDE 0683-100)
Max. short-circuit current I <sub>k</sub> 0.06 s	32.0 kA
DB drawing No.	3 Ebgw 01.51
DB material No.	237 117
Weight	13,44 kg
Customs tariff number (Comb. Nomenclature EU)	85359000
GTIN	4013364123793
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.