


ES SK 1000 (761 010)

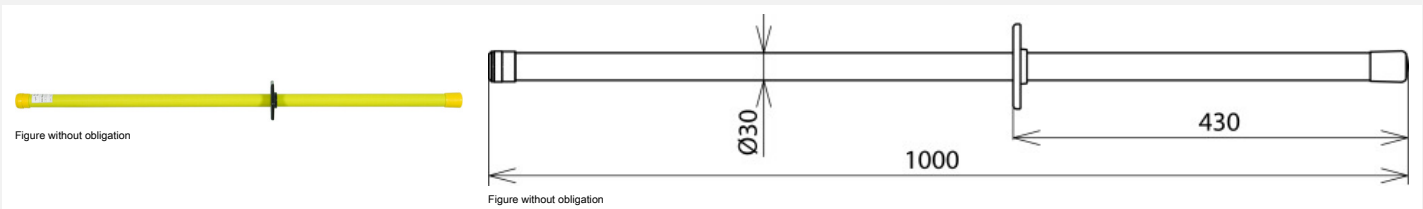

Type	ES SK 1000
Part No.	761 010
Total length (l _G)	1000 mm
Length (handle) (l _H)	430 mm
Max. load on the operating head	12 kg
Temperature range	-25 °C ... +55 °C
For use in	Indoor and outdoor installations
Material (insulating tube)	Glass-fibre reinforced polyester tube
Diameter	30 mm
Supporting head for	Hexagon shaft (width across flats 19 mm)
Anti-rotation plug-in coupling including end fitting	No
Type of device	Earthing stick
Weight	980 g
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364000155
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.