


SCS 36 1000 (763 610)

- For use as operating stick for inserting insulating protective shutters
- Handle termination with end cap

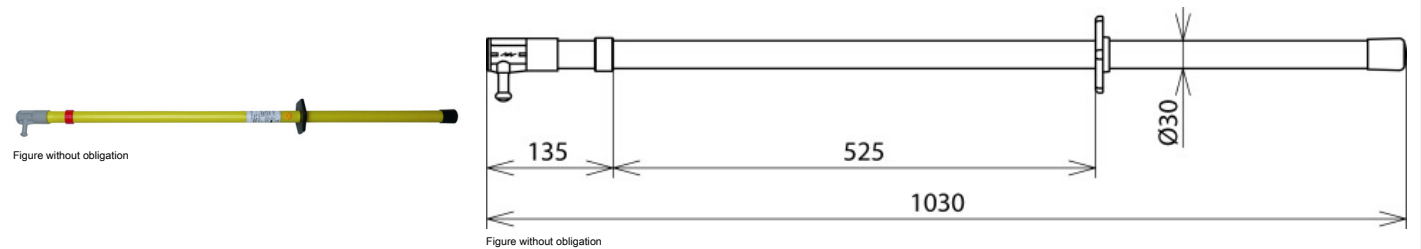

Type	SCS 36 1000
Part No.	763 610
Nominal voltage (U _N)	1 ... 36 kV
Max. load on the operating head	6 kg
Total length (l _o)	1030 mm
Insulating clearance (l _i)	525 mm
Length (handle) (l _h)	370 mm
Insertion depth (l _o)	135 mm
Standard (switching stick head)	DIN VDE V 0681-2
Standard (switching stick)	DIN VDE V 0681-1 and -2
Standard (insulating stick)	DIN VDE V 0681-1
For use at	*
For	For indoor and outdoor installations
Design	Fully insulated, solid switching stick head
Material (insulating tube)	Glass-fibre reinforced polyester tube
Material (switching pin)	Steel, plastic-sheathed
Diameter	30 mm
Anti-rotation plug-in coupling including end fitting	No
Type of device	Switching stick
Weight	962 g
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364003286
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.