


SZ HH 1060 (765 040)

- 20° angled operating head for HH fuses that are not easily accessible

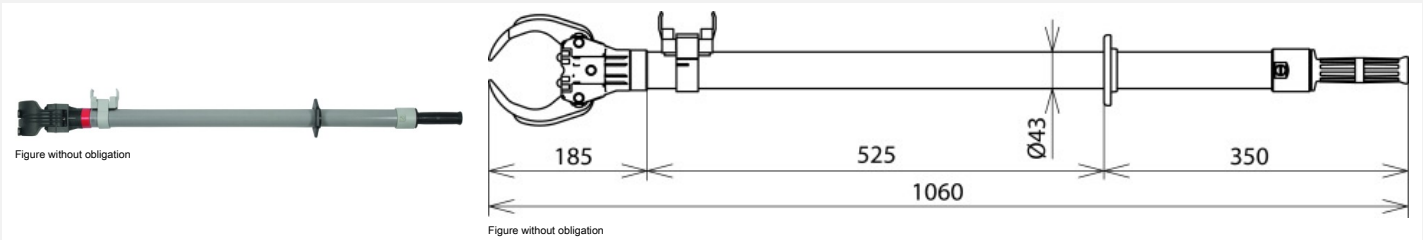

Type	SZ HH 1060
Part No.	765 040
Nominal voltage (U _N)	1 ... 36 kV
Clamping range	30 ... 50 ¹⁾ / 50 ... 90 mm
Total length (l _g)	1060 mm
Insulating clearance (l _i)	525 mm
Length (handle) (l _h)	350 mm
Insertion depth (l _o)	185 mm
Standard	DIN VDE V 0681-3
For use at	*
For	Indoor and outdoor installations
Design	Straight clamping head
Material (insulating stick)	Glass-fibre reinforced polyester tube
Material (operating head)	Glass-fibre reinforced polyamide
Material (reducing insert)	Polyamide
Material (adjustable handle)	Polyamide
Diameter	43 mm
Colour	Grey ●
Anti-rotation plug-in coupling including end fitting	No
Type of device	Fuse tong
Weight	2,13 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364093751
PU	1 pc(s)

¹⁾ Only if used with reducing insert

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.