


## IS 36 SK 1000 (766 001)

- For use as switching, operating and earthing stick
- Handle closed with end cap

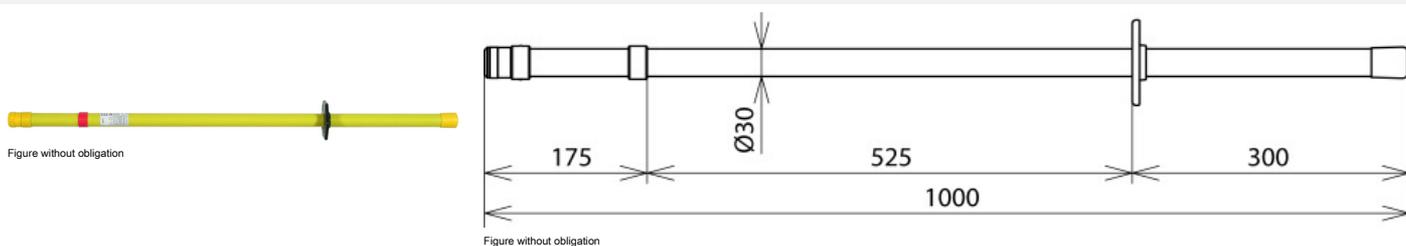

Type	IS 36 SK 1000
Part No.	766 001
Nominal voltage (U <sub>N</sub> )	1 ... 36 kV
Total length (l <sub>σ</sub> )	1000 mm
Insulating clearance (l <sub>i</sub> )	525 mm
Handle length (l <sub>H</sub> )	300 mm
Insertion depth (l <sub>o</sub> )	175 mm
Standard (insulating stick)	DIN VDE V 0681-1
For	Indoor and outdoor installations
Material	Glass-fibre reinforced polyester tube
Diameter	30 mm
For use at	*
Supporting head for	Hexagon shaft
Anti-rotation plug-in coupling including end fitting	No
Type of device	Insulating stick
Weight	416 g
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364017825
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.