


ESTC SQL STK 3000 (769 300)

- For outdoor use
- Robust aluminium cone coupling
- Telescopic stick, length continuously adjustable by star knob
- For phase screw clamps and clamps with long T pin shaft
- With plug-in coupling



Figure without obligation

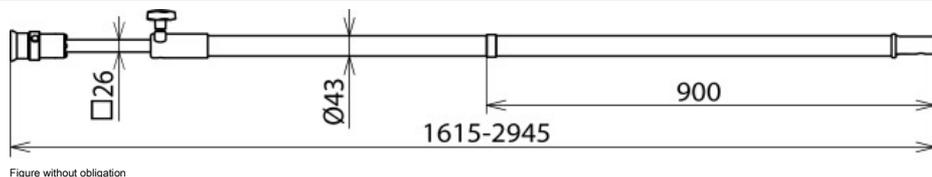

Type	ESTC SQL STK 3000
Part No.	769 300
Total length ($l_{G \max} / l_{G \min}$)	3015 / 1760 mm
Length (handle) (l_H)	900 mm
Max. load on the operating head ($l_{G \max} / l_{G \min}$)	10 / 20 kg
Temperature range	-25 °C ... +55 °C
Material (insulating tube)	Glass-fibre reinforced polyester tube
Material (threaded coupling, star knob)	Aluminium alloy
Diameter	43 mm
Supporting head for	T pin shaft
Anti-rotation plug-in coupling including end fitting	Yes
Type of device	Earthing stick
Weight	2,8 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364080867
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.