


ESTC SQL 4000 (769 400)

- For outdoor use
- Robust aluminium cone coupling
- Telescopic stick, length continuously adjustable by star knob
- For phase screw clamps and clamps with long T pin shaft

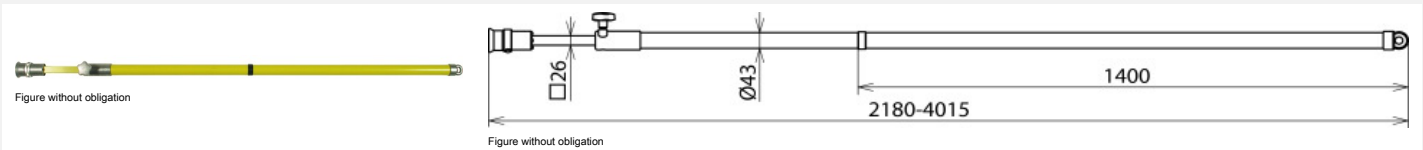

Type	ESTC SQL 4000
Part No.	769 400
Total length (l _{G max} / l _{G min})	4015 / 2180 mm
Length (handle) (l _H)	1400 mm
Max. load on the operating head (l _{G max} / l _{G min})	10 / 20 kg
Temperature range	-25 °C ... +55 °C
Material (insulating tube)	Glass-fibre reinforced polyester tube
Material (threaded coupling, star knob)	Aluminium alloy
Diameter	43 mm
Supporting head for	T pin shaft
Anti-rotation plug-in coupling including end fitting	No
Type of device	Earthing stick
Weight	3,37 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364080881
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.