


## EST KS SQL 1500 (769 503)

- Aluminium bayonet coupling with adjusting ring to fix the attached overhead line clamp
- Positive connection due to aluminium threaded coupling

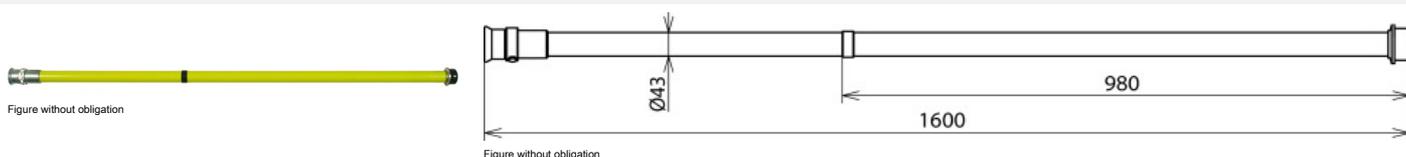

Type	EST KS SQL 1500
Part No.	769 503
Total length (l <sub>0</sub> )	1600 mm
Max. load on the operating head	20 kg
Temperature range	-25 °C ... +55 °C
Material (insulating tube)	Glass-fibre reinforced polyester tube
Material (threaded coupling)	Aluminium alloy
Diameter	43 mm
Supporting head for	T pin shaft
Type of device	Earthing stick - top section
Weight	1,65 kg
Customs tariff number (Comb. Nomenclature EU)	82055980
GTIN	4013364003996
PU	1 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.